

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

08-52-0131

Status:


Active

Overview:

[KK® Interconnection System](#)

Description:

KK® Crimp Terminal 8818, 18-22 AWG, Reel, Phosphor Bronze Tin (Sn)

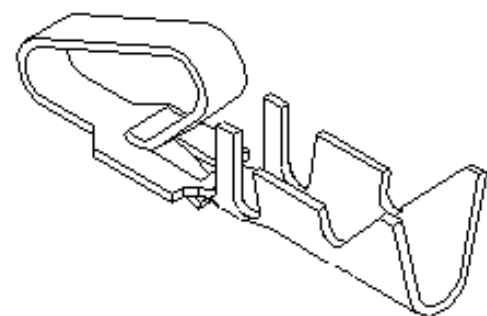

Series

image - Reference only

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Specification PS-08-50 \(PDF\)](#)

General	
Product Family	Crimp Terminals
Series	8818
Application	Power
Crimp Quality Equipment	Yes
Overview	KK® Interconnection System
Product Name	KK®

Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.41mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	N/A

Material Info	
Old Part Number	8818-A(P909)

Reference - Drawing Numbers	
Product Specification	PS-08-50
Sales Drawing	SD-8818

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

8818Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Hand Crimper	0638117500
Mini-Mac™	0638881100
Applicator	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION