

Products

- Product On-Line Catalog
- [Product Search](#)
- Evaluate
 - FAQ's
- Design a Solution
 - Catalog Cut Sheet
 - PDF-G.75X2BL6 Pr
 - Part Drawings
 - PDF-Type G 1x2 W ..
 - DWG-Type G 1x2 W ..
 - DXF-Type G 1x2 W ..
- How to Buy
 - Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Product On-Line Catalog > Product Search >

Current refinements (click to remove) Search Tips

[Part Number](#) > G1X2BL6

Your search criteria matched only one product, shown below

G1X2BL6

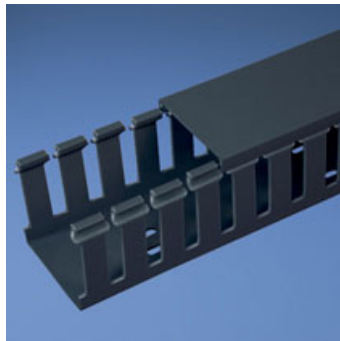

Choose from 22 sizes of Panduit Type G Wiring Duct from 0.75" x 2.0" up to 4.0" x 5.0" in color. Used for general purpose control panel wiring and to route and protect wiring in communication closets. The non-slip cover conceals all wiring and is easy to install. The d cover form a flush sidewall providing increased capacity and improved aesthetics.

Specifications

• **Base and covers sold separately**

- Made of lead-free PVC
- UL Recognized continuous use temperature: 122 °F (50°C)
- UL94 Flammability Rating of V-0
- Conforms with NFPA 79-2002 section 14.3.1 requirement for flame retardant material
- Provided with mounting holes

Features and Benefits

- Wide finger/slot design provides greater sidewall rigidity and can be used with a wide range of wire bundle sizes
- Panduit exclusive rounded edges protects hands and wiring/cabling from abrasion
- Non-slip cover stays in place during shipment, vibration and when in vertical orientation, eliminating rework
- Flush cover design holds 10-12% more wires than traditional duct designs
- Double scoreline allows quick modification for larger cabling bundles saving installation time leading to a lower installed cost
- Specially formulated lead-free material eliminates health concerns associated with PVC that contains lead
- Restricted slot design retains wire in slot for fast, easy wire installation or removal

Base and cover sold separately.

▪ Part Number	G1X2BL6
▪ RoHS Compliancy Status	Compliant
▪ Part Description	Wide finger, slotted wiring duct. Base and covers sold separately.
▪ Product Type	Type G Wide Slot Wiring Duct
▪ Material	Lead-Free PVC
▪ Color	Black
▪ CSA Certified	Yes
▪ UL Recognized (File No. E147128)	Yes
▪ Height (In.)	2.12
▪ Height (mm)	53.8
▪ Length (ft.)	6
▪ Length (mm)	1828.8
▪ Width (In.)	1.26
▪ Width (mm)	32.0
▪ CE Compliant	Yes
▪ Duct Size W x H (In.)	1.26 x 2.12
▪ Duct Size W x H (mm)	32.0 x 53.8
▪ Mounting Method	Standard Mounting Holes
▪ Pricing Description	Slotted Duct, PVC, 1"X2"X6',BLK
▪ Slot Width (In.)	0.31
▪ Slot Width (mm)	7.9
▪ Cover Part Number	C1BL6
▪ Min. Order UOM	FT
▪ Min. Order Qty.	6
▪ BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
▪ Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.