


## Bench/Machine Luminaires

### Task 1

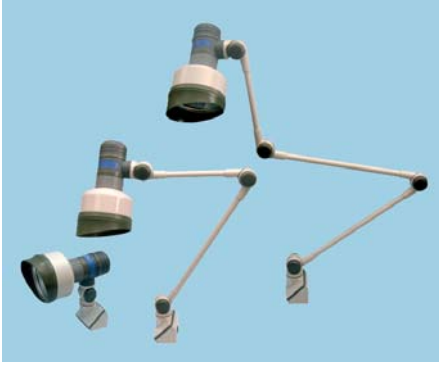

- Designed for use on mains or extra low safety voltage - can be operated on 12V, 25V, 50V, 110V and 240V
- Adjustable friction arm joints for ease of positioning
- Edison screw lampholder is particularly suitable for vibratory conditions
- Requires ES GLS lamp, max. 60W (not supplied)
- On/Off switch on head for ease of use
- Light shade polished internally for maximum light output
- IP20 rated
- Fitted with a universal base - can be horizontally or vertically mounted
- Colour co-ordinated desk clamp with trailing lead and cable gland available (not supplied)
- Powder coated for durability
- All wiring enclosed, connector block in base for ease of connection
- Complete with anti-glare visor
- Transformers available separately with secondary tapping at 12/24V
- Colour: Goosewing grey
- Light shade  $\varnothing$ : 127mm
- Arm lengths: 400 x 250mm (2 Arms), 400 x 400 x 250mm (3 Arms)

419512

Description	Order Code	Price Each
<b>Luminaires</b>		
Light - No Arms	107-9985	
Light - 2 Arms	734-640	
Light - 3 Arms	427-9141	
<b>Transformers</b>		
240V to 12/24V	107-9986	
415V to 12/24V	107-9987	
<b>Mains Lead &amp; Clamp</b>		
UK Lead	107-9995	
EU Lead	107-9998	
<b>Lamps</b>		
12V - 60W	110-6299	
25V - 60W	110-6300	
50V - 60W	110-6301	
110V - 60W	825-0170	
240V - 60W	825-0189	