


Overview

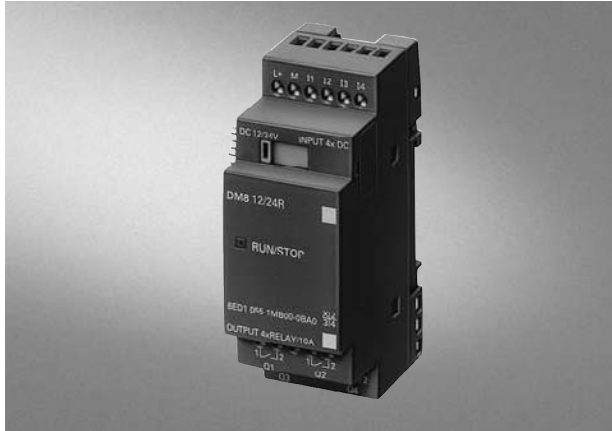

- Expansion modules for connection to LOGO! Modular
- With digital inputs and outputs or analog inputs and outputs

Ordering Data	Order No.		Order No.
LOGO! DM8 24 24 V DC supply voltage, 4 digital inputs 24 V DC, 4 digital outputs 24 V DC, 0.3 A	6ED10551CB000BA0	Accessories	
LOGO! DM8 12/24R 12/24 V DC supply voltage, 4 digital inputs 12/24 V DC, 4 relay outputs 5 A	6ED10551MB000BA1	LOGO! Manual English	6ED10501AA000BE7
LOGO! DM8 24R 24 V AC/DC supply voltage, 4 digital inputs 24 V AC/DC, 4 relay outputs 5 A	6ED10551HB000BA0	LOGO! Memory cards Memory only card, Battery card and Memory/Battery card. Supports copying and know-how protection	6ED10561DA000BA0 6ED10566XA000BA0 6ED10567DA000BA0
LOGO! DM8 230R 115/230 V AC/DC supply voltage, 4 digital inputs 115/230 V AC/DC, 4 relay outputs 5 A	6ED10551FB000BA1	LOGO!Soft Comfort V6 for programming on the PC in LAD/FBD; executes with Windows 98 onwards, Linux, MAC OSX; on CD-ROM	6ED10580BA020YA0
LOGO! DM16 24 24 V DC supply voltage, 8 digital inputs 24 V DC, 8 digital outputs 24 V DC, 0.3 A	6ED10551CB100BA0	LOGO!Soft Comfort Upgrade V1.0 upwards to V6	6ED10580CA020YE0
LOGO! DM16 24R 24 V DC supply voltage, 8 digital inputs 24 V DC, 8 relay outputs 5 A	6ED10551NB100BA0	LOGO! USB PC cable for program transmission between LOGO! and PC	6ED10571AA010BA0
LOGO! DM16 230R 115/230 V AC/DC supply voltage, 8 digital inputs 115/230 V AC/DC, 8 relay outputs 5 A	6ED10551FB100BA0	LOGO! Modem Cable DB9 RS232 external modem connection	6ED10571CA000BA0
LOGO! AM2 12/24 V DC supply voltage, 2 analog inputs 0 to 10 V or 0 to 20 mA, 10-bit resolution	6ED10551MA000BA0	LOGO! Bus Expansion Cable 2nd row expansion module cable	6ED10571BA000BA0
LOGO! AM2 PT 100 12/24 V DC supply voltage, 2 Pt100 analog inputs, tempera- ture range -50 °C to 200 °C	6ED10551MD000BA0	LOGO! Starter Kit, 12/24 V contains LOGO! 12/24RC, LOGO! PC-USB cable, LOGO!Soft Comfort V6, user manual, screwdriver	6ED10573BA000BA5
LOGO! AM2 AQ 12/24 V DC supply voltage, 2 analog outputs 0 to 10 V, 10-bit resolution	6ED10551MM000BA1	LOGO! Starter Kit, 230 V contains LOGO! 230RC, LOGO! PC-USB cable, LOGO!Soft Comfort V6, user manual, screwdriver	6ED10573AA020BA0
		LOGO! 12/24RCo & TD Starter Kit contains LOGO! 12/24RCo, LOGO! TD w/2.5m cable, LOGO!Soft Comfort V6, PC-USB cable, user manual, and screwdriver	6ED10573BA100BA0