

Link&Light



FIXING CLIPS SUPPLIED


2 METRES LINK MAINS LEAD INCLUDED



ROCKER SWITCH



ADDITIONAL LINK LEADS AVAILABLE - SEE OUR NL RANGE

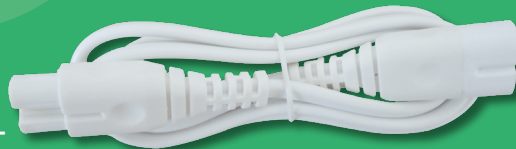

REPLACEMENT LAMPS AVAILABLE - SEE OUR N64 RANGE



 
 
LINEAR T4 UNDER CABINET LIGHTS



- **TUS6NL** requires 1 x 6W G5 T4 220mm fluorescent tube 3400K (included)
- **TUS10NL** requires 1 x 10W G5 T4 341mm fluorescent tube 3400K (included)
- **TUS16NL** requires 1 x 16W G5 T4 468mm fluorescent tube 3400K (included)
- **TUS20NL** requires 1 x 20W G5 T4 567mm fluorescent tube 3400K (included)
- Polycarbonate construction
- Individual rocker switch
- Link & light system compatible
- Incorporates plug and socket with through wiring: can be linked with up to 5 other fittings
- 2 metres link mains lead included
- See product codes NL1WH / NL50WH / NL25WH for additional link leads

T4 REPLACEMENT LAMPS

- Colour temperature: 3400K
- 8,000 hours average rated life
- Specifically designed for use with Eterna® brand fittings



Individual rocker switch

Code		L	W	H	Col	IP	M.O.M	O.P.Q
TUS6NL	6W Linkable Triphos. Fitting	270	19	45	WH	IP20	5	50
TUS10NL	10W Linkable Triphos. Fitting	390	19	45	WH	IP20	5	50
TUS16NL	16W Linkable Triphos. Fitting	520	19	45	WH	IP20	5	50
TUS20NL	20W Linkable Triphos. Fitting	620	19	45	WH	IP20	5	50
N64/1	6W T4 Ultraslim Triphos. Tube	220					10	200
N64/3	10W T4 Ultraslim Triphos. Tube	341					10	200
N64/5	16W T4 Ultraslim Triphos. Tube	468					10	100
N64/7	20W T4 Ultraslim Triphos. Tube	567					10	100