




[Back](#)

Selected Cable: 17518				
End View	Plug	Cord	Connector	End View
				
NONE	3"STRIP	SJT	386A	C13

Part Number	17518
NSN	6150-01-258-8280
Category	3 conductor plastic original equipment cords
Shielding	unshielded
Jacket Color	black
Length Feet	6'7"
Length Meters	2
Temperature Rating	60 C°C
Packaging Units Per Carton	H-100,H25
Color Coding	International
AWG Stranding	18 (41x34)
Nominal OD Inch	0.315
Nominal OD millimeter	8.00
Rating	1250 Watts 10A-125V (*)

Cord View

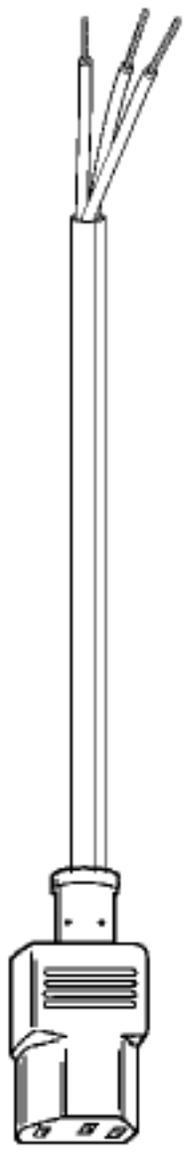

Approvals

Notes

See 17519 for 9'10" version. See 17520 for 16 gauge version. (*)Dual rated at 10A-250V.



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

