






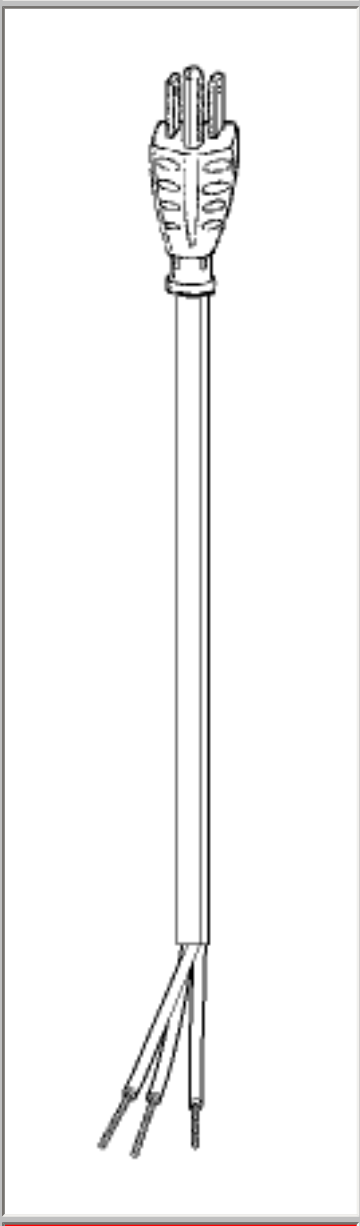
[Back](#)

Selected Cable: 17408

End View	Plug	Cord	Connector	End View
				
5-15P	290B	SJ	3"STRIP	NONE

Part Number	17408
Category	2 and 3 conductor rubber original equipment cords
Shielding	unshielded
Jacket Color	black
Length Feet	8'
Length Meters	2.44
Temperature Rating	60 C°C
Packaging Units Per Carton	B-50,S-25
Color Coding	North America
AWG Stranding	18 (16x30)
Nominal OD Inch	0.315
Nominal OD millimeter	8
Rating	1250 Watts 10A-125V

Cord View



Approvals

Notes

See 17406 for 6ft version. See 17238 for SV version. See 17409 for SJO version. See 17308 for cord holder plug version. See 40407 for SJT (plastic) version.



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

