


20mm Lithium Coin Cell Battery Holders

Thru Hole Mount (THM)

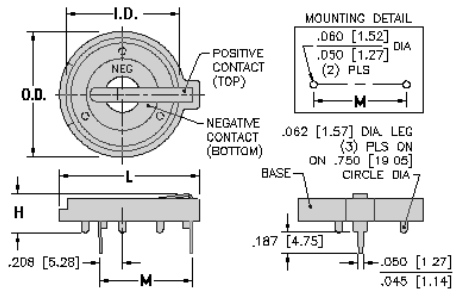

Cat. No.	Dims.	I.D.	H	L	M	O.D.
101	Inch [mm]	.796 [20.2]	.374 [9.5]	1.130 [28.7]	.807 [20.5]	.896 [22.8]
103	Inch [mm]	.796 [20.2]	.335 [8.5]	1.130 [28.7]	.807 [20.5]	.896 [22.8]
106	Inch [mm]	.796 [20.2]	.335 [8.5]	1.219 [31.0]	.807 [20.5]	1.093 [27.8]
1026	Inch [mm]	.796 [20.2]	.452 [11.5]	1.219 [31.0]	.807 [20.5]	1.093 [27.8]
Positive & Negative Contacts: .020" (0.5mm) Spring Steel, Tin Nickel Plate						
Base Material: PBT UL 94V-0, Black			Temp. Range: -60°F to +293°F (-50°C to +145°C)			