


Dickenschnellmesser

in Taschenausführung
Messflächen gehärtet, geschliffen und
geläppt


> mm <	 mm	 mm	No.	€
10	0,01	17	283-10	

Quick thickness gauge

pocket-sized portable thickness gauge,
measuring surface hardened, grounded
and micro-lapped

Comparateur d'épaisseur mini

surfaces: trempées, rectifiées et rodées

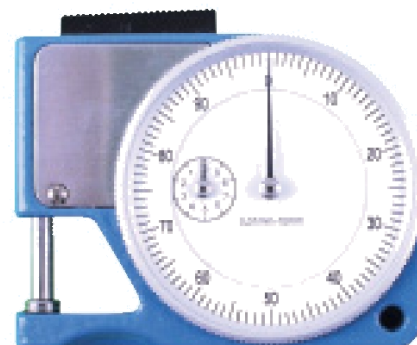




Digital-Dickenmessgeräte

Digital thickness gauges

**Contrôleurs d'épaisseur
digitaux**

Funktionen: mm/inch, Ein/Aus, Null
Features: mm/inch, on/off, zero
Fonctions: mm/inch, on/off, zero

> mm <	 mm	 inch	 mm	No.	€
15	0,01	0,0005	15	283-20	

283-20






**„QUICK MINI“ Dickenschnell-
messer**

**„QUICK MINI“ thickness
gauge**



**„QUICK MINI“ comparateur
d'épaisseur**

Funktionen: mm/inch, Ein/Aus, Null
Features: mm/inch, on/off, zero
Fonctions: mm/inch, on/off, zero

> mm <	 mm	 inch	 mm	No.	€
12	0,01	0,0005	15	283-30	

283-30



> mm <
 Ablesung mm / inch
 Bügeltiefe

Range
Reading mm / inch
Depth of frame

Capacité
Lecture mm / inch
Profondeur de l'étrier