

Parallelunterlagen aus gehärtetem Stahl

Höhentoleranz $\pm 0,01$ mm
Paarweise Toleranz IT 5

Hardened parallel supports made of steel

tolerance of height $\pm 0,01$ mm
tolerance in pairs IT 5

Jeu de cales parallèles en acier trempé

tolérance d' hauteur $\pm 0,01$ mm
tolérance en paire IT 5



580-01

Paare pairs paires	Länge length longueur	Breite width largeur	Höhe height hauteur	No.	€
12	120	10	14 / 16 / 18 / 20 / 22 / 24 / 26 28 / 30 / 32 / 35 / 40	580-01	
14	150	10	14 / 16 / 18 / 20 / 22 / 24 / 26 28 / 30 / 32 / 35 / 40 / 45 / 50	580-02	

Parallelunterlagen im Holzständer


aus gealtertem Stahl, gehärtet und paarweise
feingeschliffen
Höhentoleranz $\pm 0,01$ mm
Paarweise Toleranz IT 5

Parallel supports in wooden base

hardened, stress-relieved,
grounded and processed in pairs
tolerance of height $\pm 0,01$ mm
tolerance in pairs IT 5

Jeu de cales parallèles sur socle en bois

surfaces trempées et rodées, dressées
en paires
tolérance d' hauteur $\pm 0,01$ mm
tolérance en paire IT 5

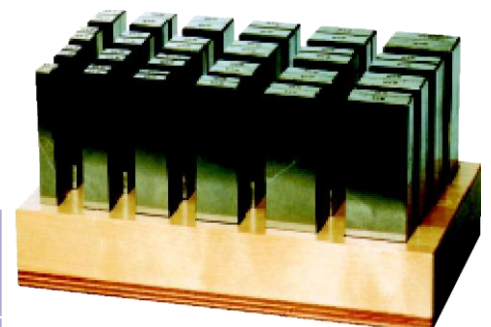

580-13

Länge length longueur	Anzahl der Paare number of pairs nombre de paires	Abmessung dimension dimension	No.	€
100 mm	20	2x5 3x6 4x7 5x8 6x9	580-11	
		2x10 3x11 4x12 5x13 6x14		
		2x15 3x16 4x17 5x18 6x19		
		2x20 3x21 4x22 5x23 6x24		
125 mm	24	8x11 10x13 12x15 14x17	580-12	
		8x16 10x18 12x20 14x22		
150 mm	24	8x21 10x23 12x25 14x27	580-13	
		8x26 10x28 12x30 14x32		
		8x31 10x38 12x40 14x42		
		8x36 10x38 12x40 14x42		