


Configuration

Dome nut	Brass CuZn39Pb3, nickel-plated
Sealing ring	Nitrile rubber
Gland body	Brass CuZn39Pb3, nickel-plated
O-ring	Nitrile rubber
Connecting thread	metric, as per EN 60423




Properties

	<ul style="list-style-type: none"> special sizes for very small and very large cable diameter easy-to-install
Temperature range	-30°C +100°C
Protection grade	IP65

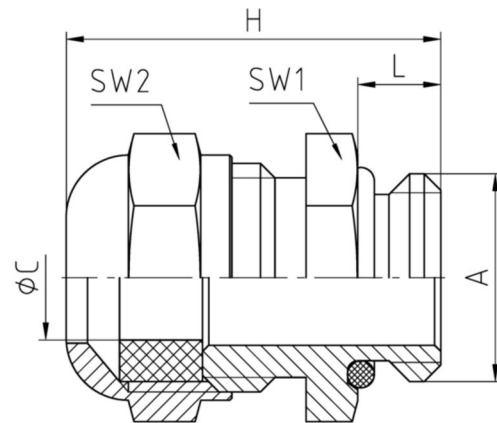

Features

Connecting thread standard length

A	ØC	L	SW1	SW2	H		Part No.
	mm	mm	mm	mm	mm	Piece	
M6x1,0	2 - 3,2	6	8	8	16,5	100	111005
M8x1,25	3 - 5	6	11	11	19	100	111006
M10x1,5	4 - 6	6	12	12	19,5	100	111010
M72x2,0	53 - 60	18	90	90	59,5	1	111072