




## OUTSIDE-2400

### Features

- Miniature Surface mounting Antenna
- 2400 - 2485MHz
- Active gain: +3dB
- VSWR <3:1
- COAX Lead with IPEX Connector
- 36 x 18 x 16mm High.
- Alternative Connectors: FME / Mini-UHF / TNC
- 2 x 3mm Fixing Screws
- -30 to +85°C

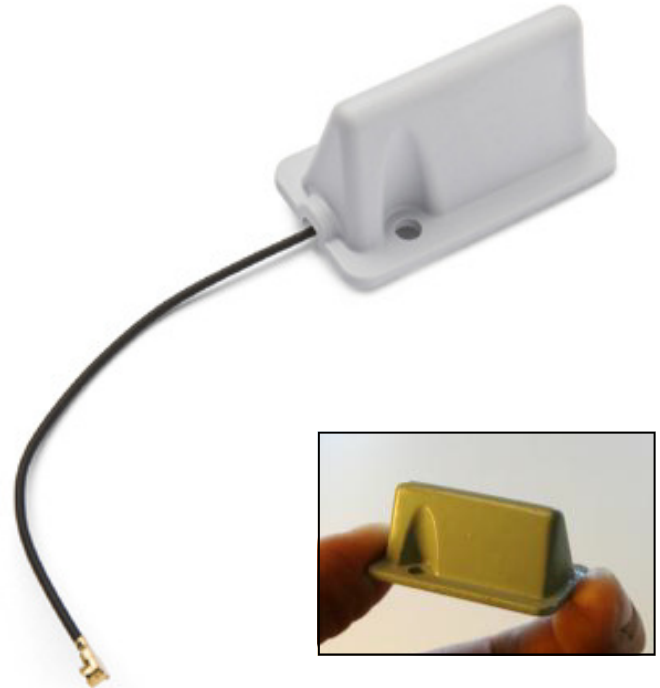

### Applications

- WLAN, Bluetooth, Zigbee
- Space Saving Applications
- M2M Industrial

### Description

A miniature rugged Gain Antenna for 2.4GHz / WLAN applications. Supplied with a 7cm lead with connector the OUTSIDE 2400 can be mounted on arbitrary materials and connect directly to the Radio interface. .

### Ordering Information

	Length	Width/Height	Cable Length	Connector
ANT-2YAG16-SMA	36mm	18 / 16mm	7cm	IPEX

