


# Max Steel Snips

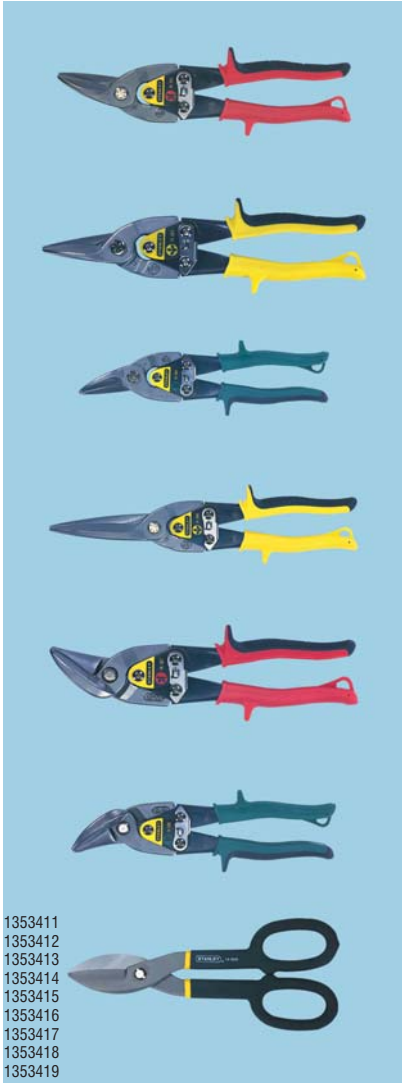

- 1353411
- 1353412
- 1353413
- 1353414
- 1353415
- 1353416
- 1353417
- 1353418
- 1353419

Max steel snips are forged alloy steel construction with chrome plated jaws. Bi-material handles provide comfort and a better grip. Features include serrated cutting edges to prevent slippage when cutting aluminium, sheet UPVC, wire mesh, leather, copper and plastic. One handed, automotive latch release with squeeze of the handle.

477918

Description	Order Code	Price Each
Left hand	135-3411	
Straight	135-3412	
Right hand	135-3413	
Long cut	135-3414	
Offset left	135-3415	
Offset right	135-3416	
175 Straight pattern snip	135-3417	
250 Straight pattern snip	135-3418	
300 Straight pattern snip	135-3419	