


6442 Large Push Button

PRODUCT IMAGE



LINE DRAWING

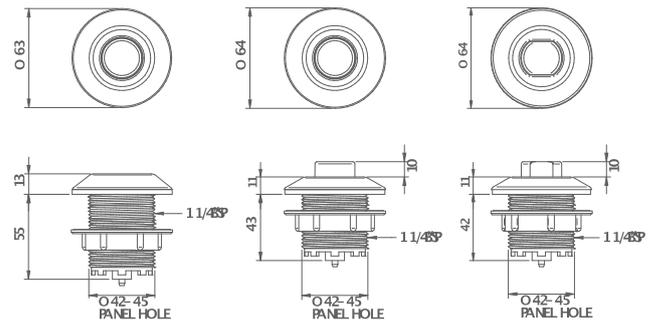

BENEFITS

- choice of button/escutcheon materials
- choice of colours
- choice of tube options
- large air volume for longer tube lengths

SPECIFICATIONS

standards/approvals	n/a
degree of protection	EN 60529 IPX4
connection method	via back entry spout, 4mm dia. or 2mm dia.
electrical rating	n/a
contact configuration	n/a
pressure range	works with 6871, 6872, 6773, 6753, 6891, 6893, 6861, 6862, 6863, 6864, 6869 – dependent on tube length
operating temperature	+10 ⁰ C to +40 ⁰ C
body material	thermoplastic
weight	plastic – 0.063Kg; metal – 0.2Kg
additional information	available as a vandal resistant version 6443

6442 Large Push Button

6442 - -

Button Type - please see note below

- A Flush Double D Button
- B Raised Double D Button (10mm High)
- C Extended Double D Button (16mm High)
- D Flush Round Button
- E Raised Round Button
- Z No Button Required

Button Finish - please see note below

- | | |
|-------------------|-----------------------|
| A White | G Red |
| B Brilliant White | M Grey Plate |
| C Chrome | N Chrome Plated Brass |
| D Gold | P Stainless Steel |
| F Black | Z None Supplied |

Escutcheon Finish - please see note below

- | | |
|-------------------|-----------------------|
| A White | G Red |
| B Brilliant White | M Grey Plate |
| C Chrome | N Chrome Plated Brass |
| D Gold | P Stainless Steel |
| F Black | Z None Supplied |

Bellows Option

- A Bellows - \varnothing 4mm Spout to suit 2311-01/08 Tube
- B Bellows - \varnothing 2mm Spout to suit 2311-03 Tube
- Z No Bellows Required

Nut and Washer Option

- A Supplied with Nut and Washer
- Z No Nut or Washer Required

Note: Finish option 'P' stainless steel can only be supplied as a flush button.
For vandal resistant version, order 6443-0001, similar to 6442-DPPA-A000 (stainless)