


▷ ISO 9654

- Slimmer bullet-nose profile combines cutting performance with manoeuvrability.
- Available with offcut retaining system. Model 405.MT is suitable for cutting piano wire \varnothing 0.4 mm.

△△ 60g.

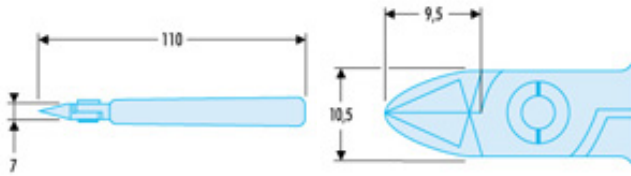

▼ Dessins Techniques

Zoom



Zoom

Zoom



Zoom

Zoom

Zoom



▼ Données Techniques

		Cu - Ni wire	Fe wire 30 HRc	Piano wire	Offcut retainer	Cut
	\varnothing mm	\varnothing mm	\varnothing mm	\varnothing mm		
405.MT	0,3 - 1,3	0,7	0,4			
406.MT	0,1 - 1,3	0,7				
406.RMT	0,1 - 1,1	0,6				
407.MT	0,1 - 1,3					