






▷ Strength to ISO 3316, DIN 3123, NF ISO3316

- Chrome finish.

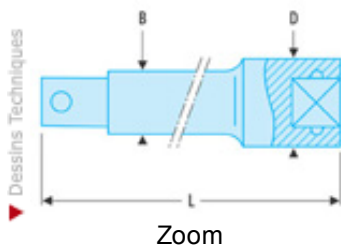

Données Techniques

		D mm	L mm	B mm	 g
	R.209	12	55	8	30
	R.210	12	100	8	45
	R.215	12	150	8	65
	R.217	12	250	8	105