

Intashield IS-400/IS-450 PCI 4 Port RS232

■ PRODUCT INFORMATION

- IS-400 Standard height
Bracket Height = 120mm
- IS-450 Low profile
Bracket Height = 80mm

■ OPERATING SYSTEMS:


- Windows 7 - 32bit & 64bit
- Windows Vista - 32bit & 64bit
- Windows XP - 32bit & 64bit

■ PRODUCT FEATURES:

- 4x9 pin, D type RS232 Serial Ports
- Universal PCI Bus - will fit into any PCI slot 5V or 3.3V
- Fully Plug & Play - simple installation and test software provided
- 1 year Warranty with option to sign up for additional free year

■ SPECIFICATIONS:

- UART: 16550
- Speed: 115,200 maximum baud rate
- Data Bits: 5, 6, 7 or 8
- Stop Bits: 1, 1.5 or 2
- Parity: odd, even, none, mark or space
- FIFO Size: 16 byte
- Quad Cable included

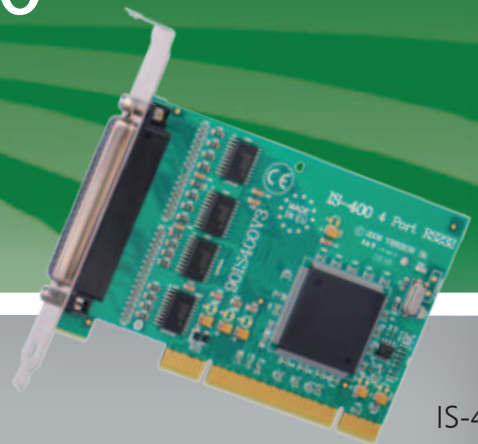

IS-400

IS-400/450

This card provides 4 industry standard RS232 serial COM ports in a single PCI slot. A fully moulded quad cable terminated in 9 pin male D plug ensures reliable connection.

As PCI is fully Plug and Play compatible your BIOS and operating system will automatically configure the card ensuring conflict free installation. Choose between standard height and low profile options.



IS-450