

MIDGET, SPF (5AG) FUSE HOLDER

- Designed for SPF (Solar Protection Fuse) • Optional cover will protect and insulate fuse • Flame resistant




3576 (THM)


SPECIFICATIONS

Base & Cover: Nylon, UL Rated 94V-0
Clips: .030 (.76) Brass, Matte Tin Plate

Rated: 30 Amps
Operating Temp. Range: -58°F to +292°F (-50°C to +145°C)

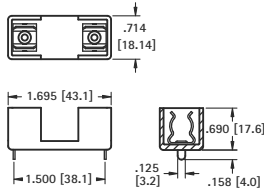


Optional Cover Cat. No. 3576C fits Cat. No. 3576 & 3574

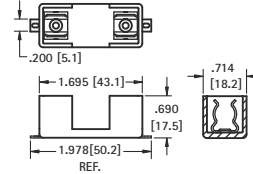

3574 (SMT)


Mounting Detail

 Mounting Detail



CAT. NO. 3574 - Holder

 CAT. NO. 3576C - Cover only



CAT. NO. 3576 - Holder

CAT. NO. 3576C - Cover only


3AG FUSE BLOCKS

- Available with fiberglass or phenolic base
- Fuse clips riveted to base for rugged applications

SPECIFICATIONS

Phenolic Base: XP, Black UL Rated 94-HB
Fiberglass Base: GPO-3 UL Rated 94 V-0
Clips: .020 (.51) Brass - Nickel Plated
Rated: 15 Amps @ 500 VAC
Operating Temp. Range: -58°F to +292°F (-50°C to +145°C)

BLACK PHENOLIC CAT. NO.	FIBER-GLASS CAT. NO.	HOLDS NO. OF FUSES	W
3536	3540	1	.500 (12.7)
3537	3541	2	1.125 (28.6)
3538	3542	3	1.750 (44.5)
3539	3543	4	2.375 (60.3)

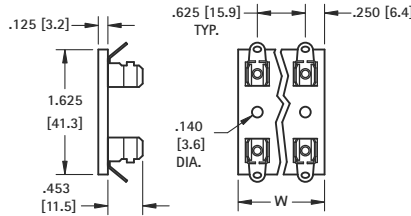

FUSE COVERS




- Made from flame retardant material
- Protects fuse from shorting and minor bumps



Can be used with clips 3512, 3512P, 3517 and 3518

MATERIAL: ABS, UL Rated 94V-0

CAT. NO.	FUSE SIZE
3517C	5mm x 20mm

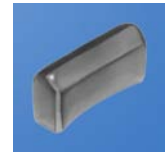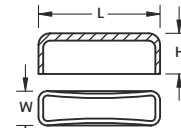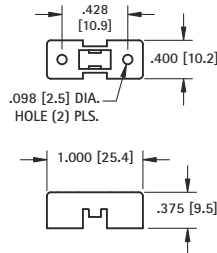

Can be used with clips or fuse holders

MATERIAL: PVC, UL Listed 94V-0

CAT. NO.	FUSE SIZE	L	W	H
3527C	5mm x 20mm	.945 (24.0)	.314 (8.0)	.512 (13.0)
3521C	2AG	.787 (20.0)	.295 (7.5)	.452 (11.5)
4245C	3AG	1.319 (33.5)	.472 (12.0)	.591 (15.0)

SUBMINIATURE FUSE HOLDERS

- Reliable spring tension assures low contact resistance
- Fuse holders allow for quick changing of subminiature fuses
- Ideal for high density circuit board applications

SPECIFICATIONS

Base: Thermoplastic, UL Rated 94V-0
Springs: Beryllium Copper, Gold Plate

Pins: Brass, Tin Plate
Current Rating: 5 Amps @ 250V AC



.335 (8.5) x .158 (4.0) FUSE

For Littelfuse 392/395 Type TE5®
 Bussmann: PC Series or equivalent




.335 (8.5) DIA. FUSE

For Littelfuse 370 Type TR5®
 Bussmann: BK-EFF series or equivalent




STURDI-MOUNT

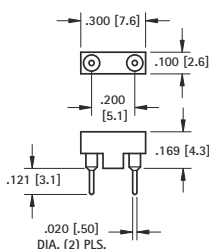


CAT. NO. 3552

LOW PROFILE

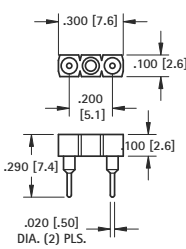


CAT. NO. 3553

STURDI-MOUNT

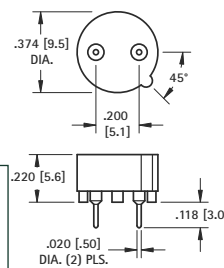

CAT. NO. 3555

LOW PROFILE

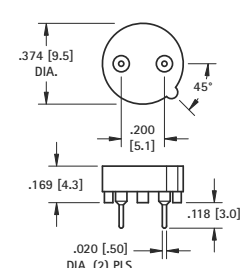

CAT. NO. 3554