


Sta-Kon®

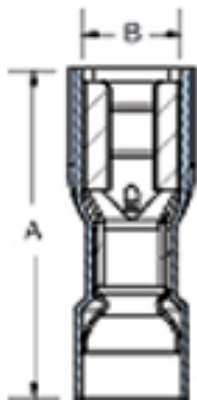

Disconnects

T&B Catalog Number:

18RA-2577

UPC Number:

78621083933

Status:

Active

Description:

Fully Insulated Nylon Female - 250 Series Disconnects For Wire Range 22-18 Length 0.97, Tab Size .250 x .032, Red

WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Unique construction of the female disconnect offers long-term dependability. Brazed seam serrated barrel provides maximum tensile strength.

General

Disconnect Type	Female - 250 Series
Insulation Type	Fully Insulated Nylon
Terminal Series	RA
Material	Brass
Finish	Electro -Tin Plated
Color	Red
Wire Range	22-18
Tab Size	.250 x .032

Dimension Information

Maximum Insulation (inches)	.165
Stock Thickness	.03
A (inches)	.97
B (inches)	.38

Specifications

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	WT145C, WT2000, WT112M, ERG4001, ERG4003
Recommended Tool	ERG4001

Packaging

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	500
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.45 lbs. per 100
Alternate Package Qty	RA2573

Application Support

Overview

Available on Website

Wire Guide Tables

Available on Website

Certifications

RoHS Compliance

Yes

Certifications



File Nbr:

E66716