

CH1

S11

SWR

117.8 m /

REF 940 m

2: 1. 0178


5 970 . 000

150 MHz

Cor

↑

CH1 Markers
Max
1: 1. 0117
3. 00000 GHz

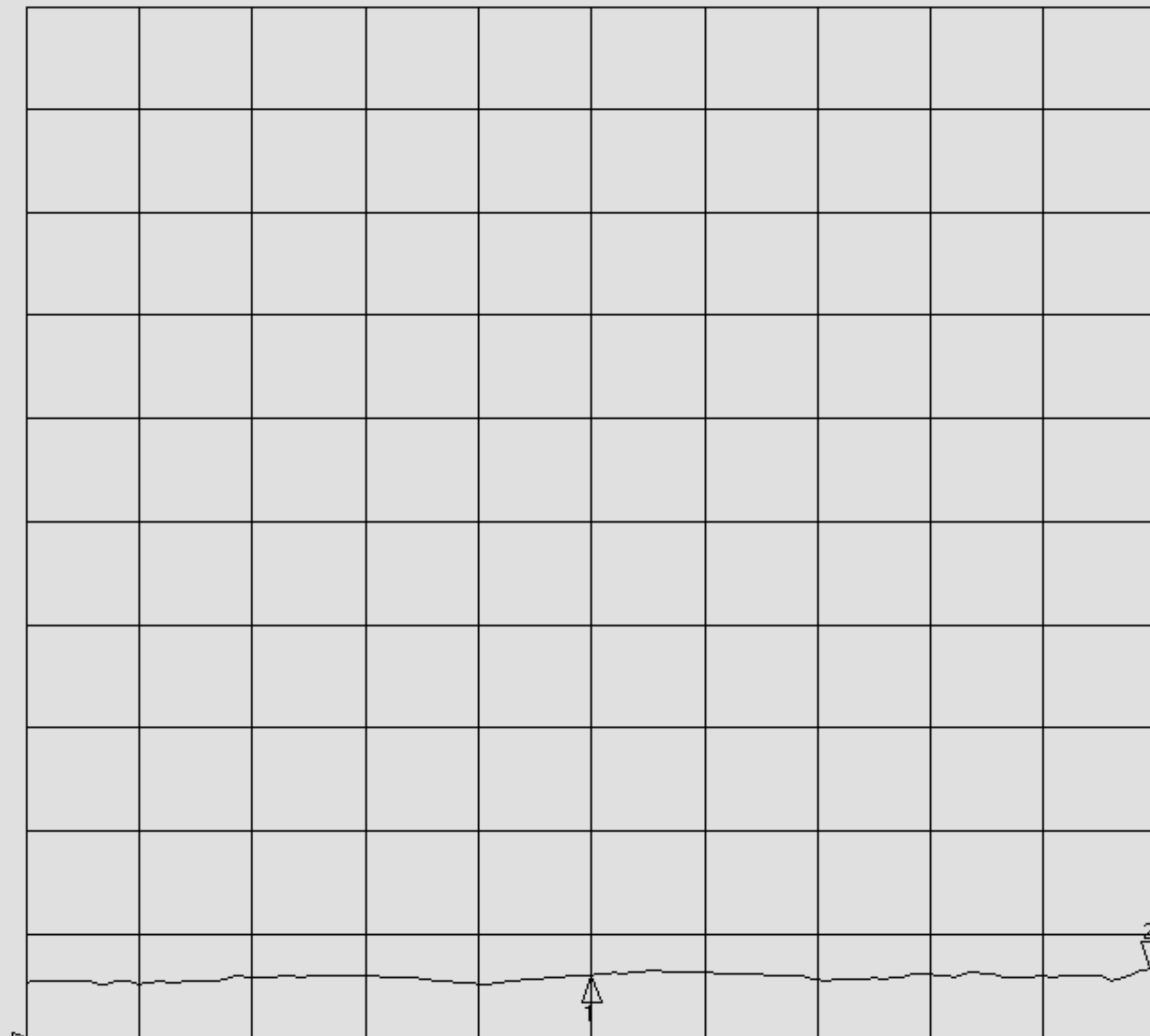

START . 030 000 MHz

STOP 6 000 . 000 000 MHz