




▷ NFE 75-001, NFE 75-002

- AS.6L 6 needle files (RD.DRD.DPE.CAR.TRI.PAM).
- AS.12L 12 needle files (RD, DED, PDE, FS, CT, CAR, TRI, PAM, BAR, PAMBR, CRO, OV).
- T0 for rough filing, T2 for precision filing, T4 for finishing.
- Packaging BC cardboard box; BP plastic box; TP plastic wallet.


▼ Dessins Techniques

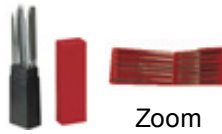

Zoom

Zoom



File type	Packaging	Length mm	 g
AS.12LBC100T0	T0 BC	100	41
AS.12LBC100T2	T2 BC	100	42
AS.12LBP140T0	T0 BP	140	114
AS.12LBP140T2	T2 BP	140	108
AS.12LBP140T4	T4 BP	140	109
AS.6L140T0	T0 TP	140	86
AS.6L140T2	T2 TP	140	85
AS.12LBP160T0	T0 BP	160	136
AS.12LBP160T2	T2 BP	160	135
AS.12LBP160T4	T4 BP	160	134
AS.6L160T0	T0 TP	160	99
AS.6L160T2	T2 TP	160	98
AS.12LTP180T0	T0 TP	180	236
AS.12LTP180T2	T2 TP	180	233
AS.12LTP180T4	T4 TP	180	232
AS.6L180T0	T0 TP	180	113
AS.6L180T2	T2 TP	180	115

▼ Données Techniques