


**KEMET Part Number: PME271Y433MR30**  
(P271HH332M250A)

Capacitor, film, 3300 pF, +/-20% Tol, -40/+100C, Safety: Y2, 250VAC, Lead Spacing=10.2 mm

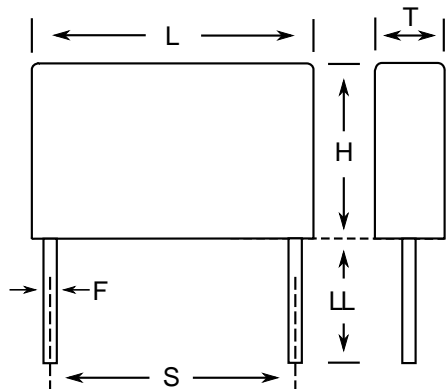

**Dimensions (mm)**

Symbol	Dimension	Tolerance
L	13.5	MAX
H	8.2	MAX
T	4.1	MAX
S	10.2	+/-0.4
LL	30	+5
F	0.6	+/-0.05

**Packaging Specifications**

Package Kind:	Bulk
Package Quantity:	1000

**General Information**

Supplier:	KEMET
-----------	-------

**Specifications**

Capacitance:	3300 pF
Rated Temperature:	100C
Voltage AC:	250VAC
Tolerance:	+/-20%
Body Type:	Radial Molded
Dielectric:	Metallized Paper
Application:	Safety: Y2
Temperature Range:	-40/+100C
Electrical Name (Other):	Self Resonant Frequency
Electrical Value (Other):	30
Electrical Units (Other):	mHz
Dissipation Factor @ 1 kHz:	1.3%
Insulation Resistance:	12 GOhm
Maximum dVdT:	2000v/us

**Agency Approvals**

Approvals:	ENEC,UL,cUL,CQC
------------	-----------------