

20 W 6 V

Low-voltage halogen lamps without reflector



Product features

- Xenon instead of krypton as the filler gas (XENOPHOT HLX versions)
- Luminous flux up to 10 % higher with same power consumption (XENOPHOT HLX versions)

Technical data

Electrical data


Nominal wattage	20 W
Nominal voltage	6 V

Light technical data

Nominal luminous flux	460 lm
Luminous flux	480 lm

Dimensions & weight

Diameter	9.0 mm
Light center length (LCL)	19.5 mm
Length	31.0 mm
Filament diameter	0.8 mm

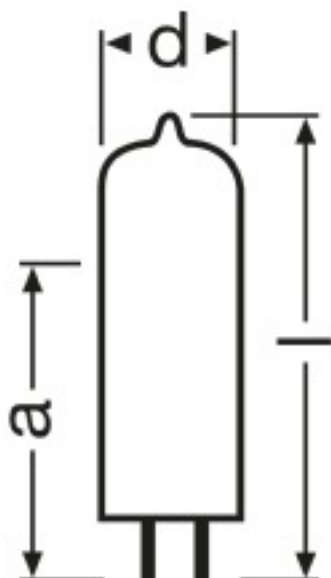

Product line drawing



Base

Lifespan

Lifespan	100 h
----------	-------

Additional product data

Base (standard designation)	G4
-----------------------------	----

Country specific categorizations

Order reference	64250 HLX
-----------------	-----------



Burning position

Logistical Data

Product code	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Gross weight	Volume
4050300012407	Folding carton box 1	25 mm x 23 mm x 70 mm	3.60 g	0.04 dm ³
4050300890999	Shipping carton box 40	121 mm x 107 mm x 144 mm	190.50 g	1.86 dm ³

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.