




FGG.00.302.CLAD35

MECHANICAL DETAILS

Shell Style Model	FG* : Straight plug cable collet
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Housing Material	Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces
Cable Fixing	2.8 - 3.5 mm
Variant 2	:

	A	L	M	S1	S2
Mm.	6.4	28.5	20.5	5.5	5
In.	0.25	1.12	0.81	0.22	0.20

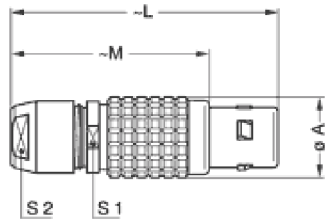


Available Download

[unipole_multipole.pdf](#)


PERFORMANCE DETAIL

Insert	0.302 : 2 Low Voltage
Insulator	L: PEEK
Specifications	
Contact Type:	Solder
Max. Matings:	5000
Contact Dia.:	0.5 mm (0.02in)
Bucket Dia.:	0.4 mm (0.016in)
Max. Solid	0.09 mm ² (AWG 28)
Max. Stranded	0.05 mm ² (AWG 30)
R (max):	8.7 mOhm

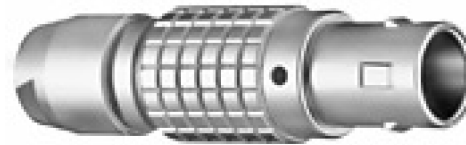

OTHER CHARACTERISTICS

Shell Style/Model	Libellé
IP Rating	50

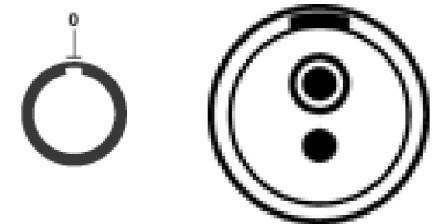

Related links

- [Contact](#)
- [Quote Request](#)
- [Catalogs Downloads](#)
- [Catalogs Requests](#)
- [Sample Request](#)
- [3D drawings](#)