

Sentinel® Connector Systems Inc.


1953 Stanton Street

York, Pa. 17404

PART NO.: 110S080810-24

* THIS PRODUCT USES NO PARTITIONS BETWEEN CONDUCTOR SLOTS *

- * EIGHT CONDUCTOR MODULAR PLUG
- * FOR FLAT, OVAL OR ROUND CABLE
- * FOR SOLID OR STRANDED CONDUCTORS
- * FOR CONDUCTORS WITH MAXIMUM O.D. OF .040
- * USES .014 CONTACT
- * SHIELDED VERSION MODULAR PLUG

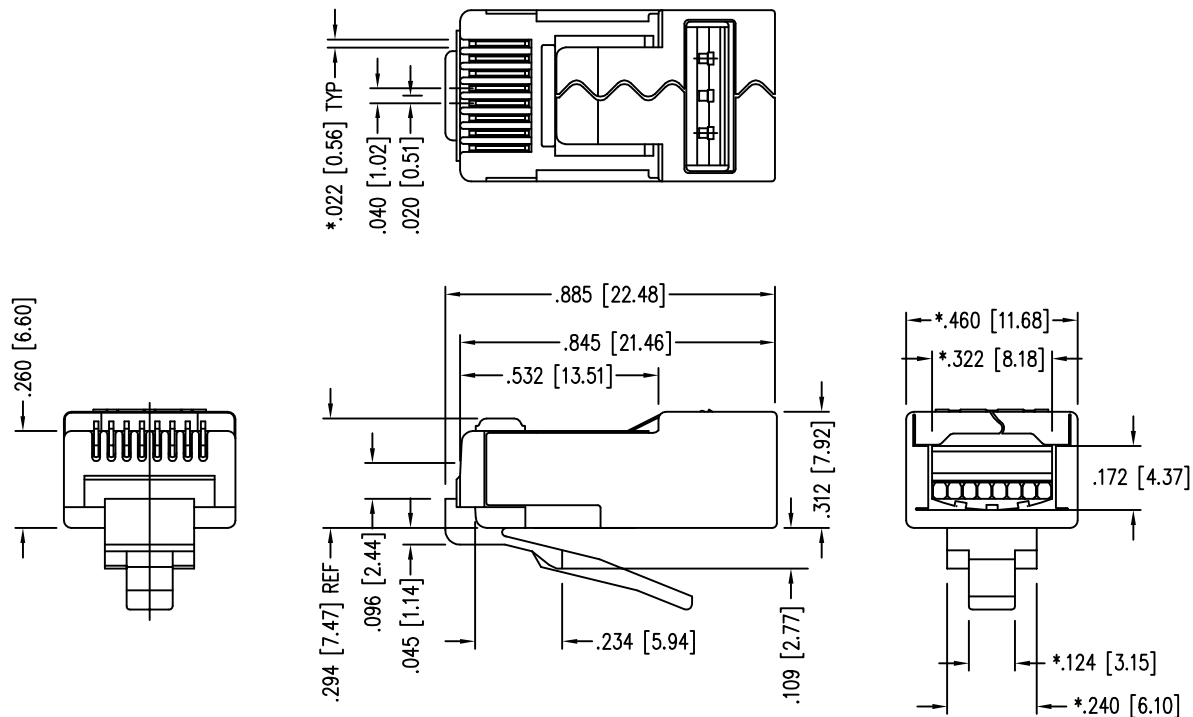


SPECIFICATIONS :

CONTACT MATERIAL:	PHOSPHOR BRONZE - .014 THK
CONTACT PLATING:	50 MICRO-INCH : OTHER PLATING OPTIONS AVAILABLE SELECTIVE 24 CARAT HARD GOLD PLATE IN CONTACT AREA OVER 100 MICRO-INCH MINIMUM NICKEL PLATE PER CURRENT SELECTIVE GOLD PLATING REQUIREMENTS.
PLUG MATERIAL:	POLYCARBONATE
SHIELD MATERIAL:	.012 THK CDA-260 1/4 HARD BRASS
SHIELD PLATING:	100% TIN, 100-150 MICRO-INCH TIN PLATED
PLUG TOLERANCES AND DIMENSIONS:	* COMPLIES WITH ANSI/TIA-1096-A REQUIREMENTS
FLAME AUTO EXTINGUISH	94-V0 - File# E188111
OPERATION TEMPERATURE:	-40°C TO +85°C
INSERTION/EXTRACTION LIFE:	1000 CYCLES
CONTACT RESISTANCE:	10 MILLOHMS MAX.
CURRENT/VOLTAGE:	30 VAC/42 VDC AT 1.5 AMPS

(RoHS COMPLIANT)

* FORMER COMPLIANCE, FCC PART 68.500

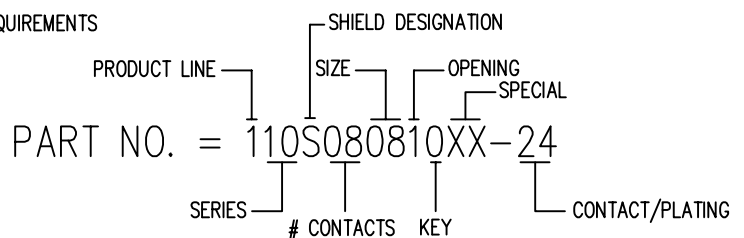

SD300026 RECOMMENDED HAND TOOL FROM SENTINEL = (900000/900208-2) OR (900005/900216-2)

4/17/12 C2
1/13/10 C1
1/06/07 C0