

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51021-0200](#)
Status: **Active**
Overview: [PicoBlade™](#)
Description: 1.25mm Pitch PicoBlade™ Wire-to-Wire and Wire-to-Board Housing, Female, 2 Circuits

Documents:

- [3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-51021-001 \(PDF\)](#)
[Product Specification PS-51021-002 \(PDF\)](#)
[Product Specification PS-51021-009 \(PDF\)](#)
[Product Specification PS-51021-010 \(PDF\)](#)
[Product Specification PS-51021-011 \(PDF\)](#)
[Product Specification PS-51021-022 \(PDF\)](#)
- [Product Specification PS-51021-023 \(PDF\)](#)
[Product Specification PS-51021-024 \(PDF\)](#)
[Product Specification PS-51021-025 \(PDF\)](#)
[Product Specification PS-51021-026 \(PDF\)](#)
[Product Specification PS-51021-027 \(PDF\)](#)
[Product Specification PS-51021-028 \(PDF\)](#)
[Packaging Specification SPK-51021-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	51021
Application	Signal, Wire-to-Board, Wire-to-Wire
MolexKits	Yes
Overview	PicoBlade™
Product Name	PicoBlade™
UPC	800753575592


Physical

Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	26.150/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Stackable	No
Temperature Range - Operating	-40°C to +85°C

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-51021-001
Product Specification	PS-51021-001, PS-51021-002, PS-51021-009, PS-51021-010, PS-51021-011, PS-51021-022, PS-51021-023, PS-51021-024, PS-51021-025, PS-51021-026, PS-51021-027, PS-51021-028, RPS-51021-001, RPS-51021-002, RPS-51021-003, RPS-51021-004, RPS-51021-006, RPS-51021-007, RPS-51021-008, RPS-51021-009, RPS-51021-010, RPS-51021-011, RPS-51021-012, RPS-51021-013,

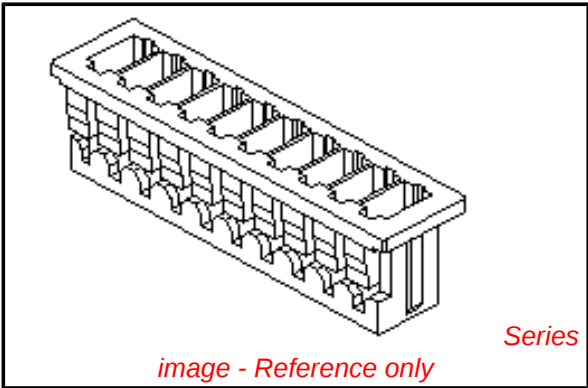

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[51021Series](#)

Mates With
[51047](#) Crimp Housing, [53047](#) PCB Header, [53048](#) PCB Header, [53261](#) PCB Header, [53398](#) PCB Header

Use With
[50058](#) Crimp Terminal, [50079](#) Crimp Terminal

RPS-51021-014, RPS-51021-015, RPS-51021-018,
RPS-51021-020, RPS-51021-021, RPS-51021-023,
RPS-51021-024, RPS-51021-025, RPS-51021-028,
RPS-51021-030, RPS-51021-031, RPS-51021-032,
RPS-51021-033, RPS-51021-034, RPS-51021-037,
RPS-51021-038, RPS-51021-039, RPS-51021-040,
RPS-51021-041, RPS-51021-042, RPS-51021-043,
RPS-51021-044, RPS-51021-045, RPS-51021-046,
RPS-51021-047, RPS-51021-048, RPS-51021-051,
RPS-51021-052, RPS-51021-053, RPS-51021-054,
RPS-51021-055, RPS-51021-056, RPS-51021-057,
RPS-51021-058, RPS-51021-059, RPS-51021-060,
RPS-51021-061, RPS-51021-062, RPS-51021-063,
RPS-51021-064, RPS-51021-065, RPS-51021-066,
RPS-51021-067, RPS-51021-068, RPS-51021-071,
RPS-51021-072, RPS-51021-073, RPS-51021-074,
RPS-51021-076, RPS-51021-077, RPS-51021-079,
RPS-51021-080, RPS-51021-081, RPS-51021-084,
RPS-51021-085, RPS-51021-086, RPS-51021-089,
RPS-51021-091, RPS-51021-092, RPS-51021-096,
RPS-51021-097, RPS-51021-101, RPS-51021-102,
RPS-51021-103, RPS-51021-104, RPS-51021-105,
RPS-51021-107, RPS-51021-108, RPS-51021-112,
RPS-51021-114, RPS-51021-117, RPS-51021-118,
RPS-53398-002, RPS-53398-037, RPS-53398-038,
RPS-53398-039
SD-51021-**00, SD-51021-002

Sales Drawing

This document was generated on 07/29/2013

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION