

SOLDERPRO™ 120

Specifications	
Length: W/Cap	254 mm (10 in)
W/Soldering tip	245 mm (9.7 in)
Weight (when gas-filled)	265 g
Approximate temperature soldering tip	250–550°C (480–1000°F)
Torch	1300°C (2400°F)
Gas container capacity	38 ml
Operating capacity (one gas filling)	120 min. at mid setting

Packing		
Item	PRO-120	PRO-120K
Packing (Inner Box Carton)	12 / 48	12 / 24
Packaging	Blister/ Card	Tool Case W/ Color Box
Master Carton (L x W x H cm)	44.5x42.7x33.6	58.2x32.7x38.8
CU.FT.	2.3'	2.6'
N.W. (kg)	13.0	16.5
G.W. (kg)	14.2	18.5



PRO-120

PRO-120K

SOLDERPRO™ 120

30W-125W POWER RANGE

Cordless Butane Products At The Leading Edge

Automatic Ignition Portable Multi-function Heat Tool

Applications:

- Automotive and truck repairs
- Aviation service and repair
- Electrical components
- Environmental splicing
- Infield repairs
- Jewelry repair
- Loosen rusted nuts and bolts
- Maintain switch panels
- Sensitive IC boards
- Shrink tubing
- Soften window caulking
- Solder circuit boards
- TV cable systems
- Repair television sets, meters, switch boards

Features:

Equivalent to a power range 30-125 Watt. Cordless, simple, safe operation anywhere. Ready to use 15 seconds after ignition. Tank contains fuel for 120 minutes of operation. No cords, can be used anywhere. No electrical interference. Comes with soldering tip and protective cap.



30W-125W POWER RANGE




PRO-120




SOLDERPRO™ 120

Basic Tips

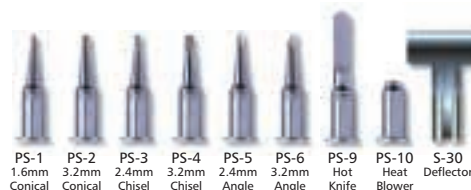

PS-1 1.6mm Conical
PS-2 3.2mm Conical
PS-3 2.4mm Chisel
PS-4 3.2mm Chisel
PS-5 2.4mm Angle
PS-6 3.2mm Angle
PS-9 Hot Knife
PS-10 Heat Blower
S-30 Deflector

Patents Pending
Worldwide

Color: 

*The Benchmark of cordless heat tools for the most demanding customer.
Auto-ignition with versatility in the power range 30W-125W.
If you want The Industry Leader, choose the Pro-120*

