


---

Item no.: 243-211  
Product description: CONNECTOR FOR EIB APPLICATIONS

---

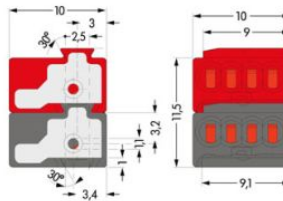

Produkt kann von Bild abweichen / product may differ

Packing unit 500 pieces

RoHS compliant

Product group	7 (Push Wire Conn.)
Cross section to [AWG]	18 AWG
Cross section to [AWG]	20 AWG
Cross section [AWG]	22 - 0.6 mm
Diameter to	0.8 mm
Diameter to	1 mm
Measured voltage EN	100 V
Current intensity EN	6 A
Weight	1.6 g
Color	dark gray/red assembled
Wiring type	Side-entry
No. of connection Points	8
No. of potentials	2
Height	11.5 mm
Height	0.453 in
Width	10 mm
Width	0.394 in
Depth	10 mm
Depth	0.394 in

Strip length from  
Strip length to  
Strip length

5 mm  
6 mm  
0.22 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
243-211	ABS	10-HN17750340X	100	6	4x0,5-1,0
243-211	CSA	18677-31	150	7	22-20

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected