

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

02-06-2103

Status:

Active

Overview:

Standard .062" Pin and Socket Power Connectors

Description:


1.57mm Diameter, Standard .062" Pin and Socket Crimp Terminal, Series 1560, Male, with Tin (Sn) Plated Brass Contact, 18-24 AWG, Bag

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	1560
Application	Power
Crimp Quality Equipment	Yes
MolexKits	Yes
Overview	Standard .062" Pin and Socket Power Connectors
Packaging Alternative	02-06-2101 (Reel)
Product Name	Standard .062"
UPC	800753616097
Physical	
Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.120/g
Packaging Type	Bag
Plating min - Mating	0.508µm
Plating min - Termination	0.508µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.52-3.05mm
Wire Size AWG	18, 20, 22, 24
Wire Size mm²	N/A
Material Info	
Old Part Number	1560-(P901)L
Reference - Drawing Numbers	
Sales Drawing	SD-1560-*

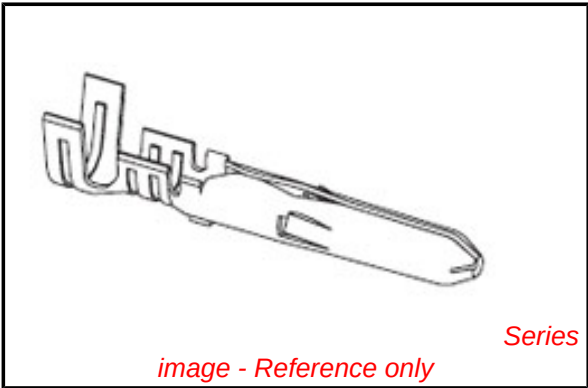

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

1560Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Insertion Tool	0011020001
Manual Extraction Tool	0011030002
Hand Crimper - DISTRIBUTION ONLY	0638111000
Hand Crimp Tool for Standard 1.57mm Pin and Socket Crimp Terminals, 18-24 AWG	0638191300

This document was generated on 10/21/2013

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION