 


H320R




**Receptacle IEC 320 Compatible**



| Description                        | Catalog Number  |
|------------------------------------|-----------------|
| 20/16A 250V AC IEC straight blade. | <b>H320R</b>    |
| For Ring Terminal connection.      | <b>H320RRT*</b> |

Note: \*Not UL Listed.

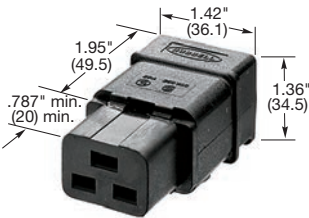

H320C




**IP20**  
SUITABILITY

**Connector**



| Description                        | Catalog Number |
|------------------------------------|----------------|
| 20/16A 250V AC IEC straight blade. | <b>H320C</b>   |

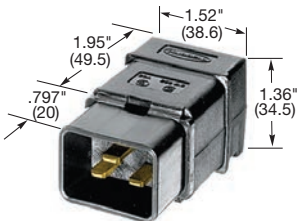

H320P




**IP20**  
SUITABILITY

**Plug IEC 320 Compatible**



| Description                        | Catalog Number |
|------------------------------------|----------------|
| 20/16A 250V AC IEC straight blade. | <b>H320P</b>   |

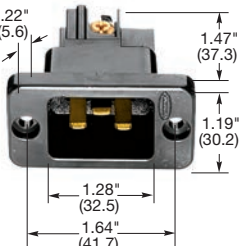

H320B




**Inlets**



| Description                                             | Catalog Number |
|---------------------------------------------------------|----------------|
| 20/16A 250V AC IEC straight blade.                      | <b>H320B</b>   |
| 20/16A 250V AC IEC straight blade with retention clamp. | <b>H320BL</b>  |

Note: See page A-63 for technical information.

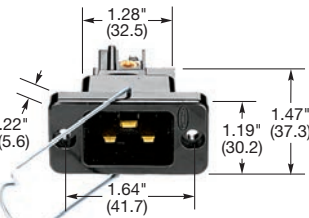

H320BL

Dimensions in Inches (mm)