


G12M Greenback



The G12M Greenback has evolved over the decades but still retains its essential, sought-after tone. Angus Young has been a Greenback devotee since the early days of AC/DC. This model is voiced with additional broad mid-range attack and restrained top-end to give a forward, punchy attitude to chords and a searing lead tone without fizz. With its well-controlled low-end it can be used singly in low-powered amps, or in multiples for high-power rock heads. It's an ideal speaker to bring drive and definition to modern high gain amps.

8 Frequency Response

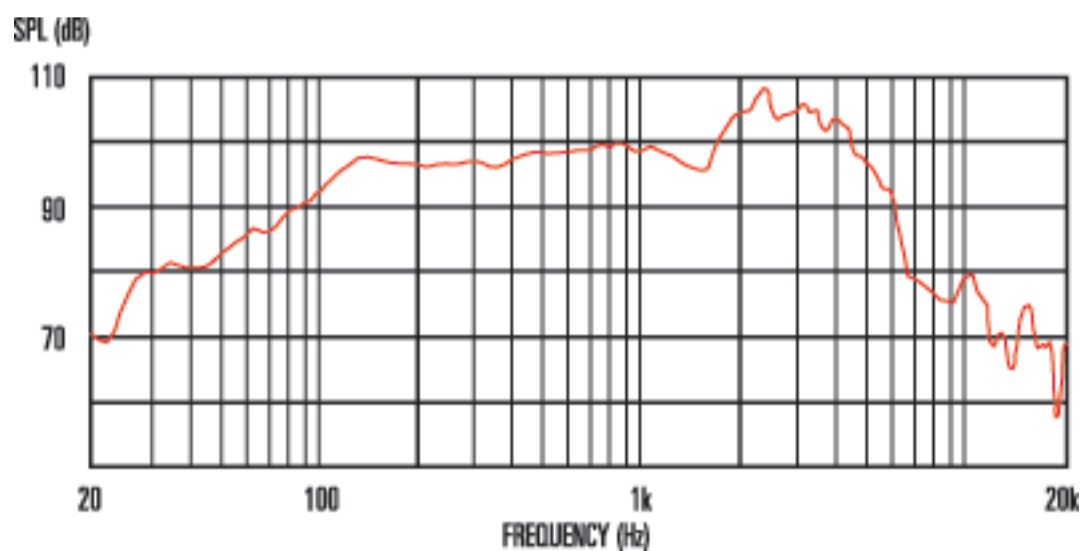

General Specifications

Nominal diameter	12", 305mm
Power rating	25Wrms
Nominal impedance	Available 8 or 16
Sensitivity	98dB
Chassis type	Pressed steel
Voice coil diameter	1.75", 44.5mm
Voice coil material	Round copper
Magnet type	Ceramic
Magnet weight	35oz, 0.99kg
Frequency range	75-5000Hz
Resonance frequency, Fs	75Hz
DC resistance, Re	Available 6.7 or 13.1

Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	5.9", 150mm
Mounting slot dimensions	0.31", 7.9mm Ø
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	5.1", 130mm
Unit weight	7.9lb, 3.6kg