
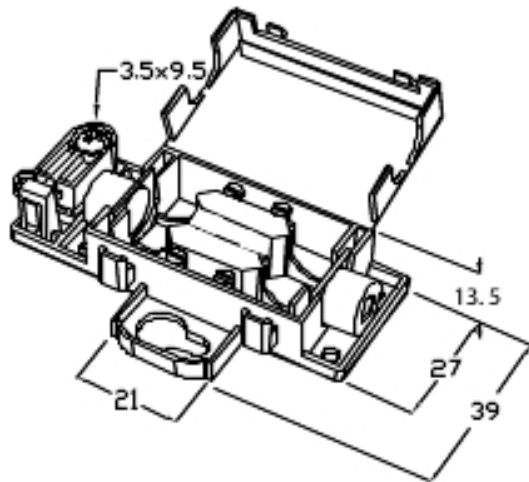


THB.110.A6B

TeeBox 2.5mm conductor max IP44 rated Screw fixing 2 cable entries, 3 poles wire protected

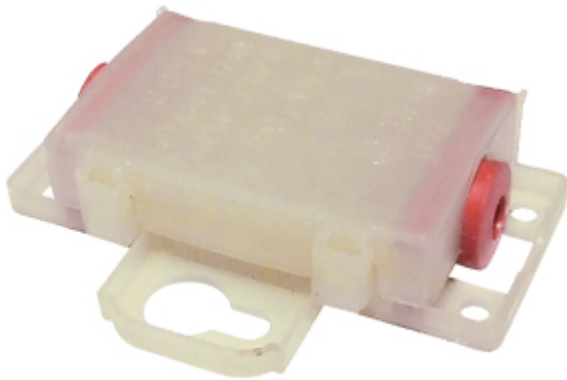

PRODUCT SPECIFICATIONS

Temperature "T" rating	T85
Maximum cable diameter (mm)	9
Fixing system	Screw
Cable entries	2
Number of poles	3
Terminal type	Screw - wp
Body material	PA66
Max conductor size (Sq mm)	2.5
Max current (A)	24
Max voltage (V)	450
Minimum temp rating °C	-40
Max temp rating °C	125
IP rating	44