


The original ball end hex key



- Ball End inserts into screw at a 25° angle
- 25° angle allows natural hand and wrist movement
- Superior Ball End strength and working angle
- Ball End saves time by quickly funneling tool into screw

Color Coded

-  Inch
-  Metric

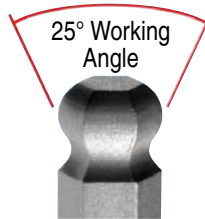




 
BONDHUS
LIFETIME WARRANTY
If any Bondhus® tool breaks or fails to meet your expectations in any way, simply return it. We will replace it free of charge.




High Torque Steel:


Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel.

FINISH OPTIONS:

-  **ProGuard** DRY SURFACE TECHNOLOGY DST Corrosion-resistant finish: Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes.
-  **BriteGuard** FINISH Next generation chrome finish: Traditional plated tool look with superior protection and durability.
-  **GoldGuard** FINISH Real 14 karat gold finish: Superior protection and durability over traditional chrome and the look and shine of real gold.
-  **ColorGuard** FINISH Color-coded protective finish: Durable color-coded finish for superior protection and easy tool identification.

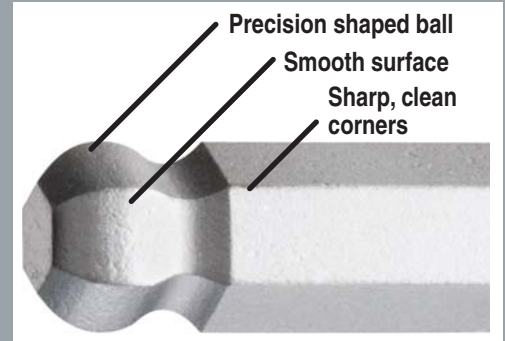

Bondhus Ball End tools feature unrivaled precision machining

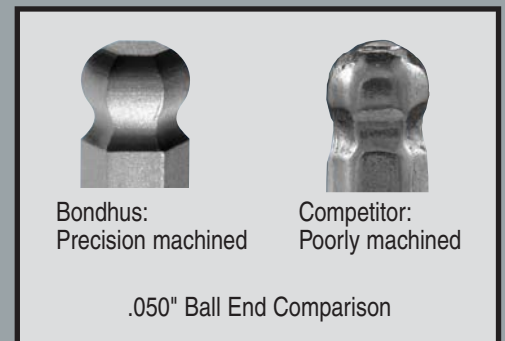


Bondhus: Precision machined

Competitor: Poorly machined

.050" Ball End Comparison

All Bondhus Ball End tools feature a precise 25° working angle

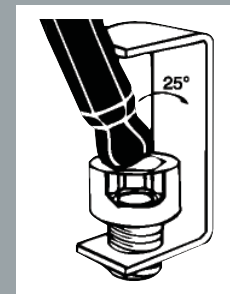

25° working angle allows tool to work in hard to reach places (20° working angle on BallStar™ Tip tools)



ProGuard™ Sets



Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY
Inch	10945	BLX7	7	Long	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"	1
	10932	BLX8	8	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1
	10938	BLX10	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1
	10936	BLX12	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1
	10937	BLX13	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1
	10935	BLX15	15	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 7/16, 1/2" (in vinyl roll up pouch)	1
	10933	MBLX13	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8" (in metal box)	1
16037	BLX13XL	13	Extra Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	10946	BLX6M	6	Long	1.5, 2, 2.5, 3, 4, 5mm	1
	10992	BLX7M	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1
	10999	BLX9M	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1
	10995	BLX15M	15	Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1
	10989	MBLX13	13	Long	1.27, 1.5, 2, 2.5, 3, 4, 5, 6, 8, 10, 12, 14, 17mm (in metal box)	1
	16099	BLX9MXL	9	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1



BriteGuard™ Sets



Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY
Inch	16938	BLX10B	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1
	16936	BLX12B	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1
	16937	BLX13B	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1
Metric	17046	BLX6MB	6	Extra Long	1.5, 2, 2.5, 3, 4, 5mm	1
	17092	BLX7MB	7	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1
	17099	BLX9MB	9	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1
	17095	BLX15MB	15	Extra Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1
	16999	BLX9MB	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1



GoldGuard™ Sets



Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY
Inch	37938	BLX10G	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1
	37936	BLX12G	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1
	37937	BLX13G	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1
Metric	38046	BLX6MG	6	Long	1.5, 2, 2.5, 3, 4, 5mm	1
	38092	BLX7MG	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1
	38099	BLX9MG	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1
	38095	BLX15MG	15	Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1



ColorGuard™ Sets



Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY
Inch	69637	BLX13XLCG	13	Extra Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1
Metric	69699	BLX9MXLCG	9	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1
	69499	BLX9MCG	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1

Bondhus Corporation

1400 E Broadway • PO Box 660 • Monticello, MN 55362
Tel: 763-295-2162 • Toll Free: 800-328-8310 • Fax: 763-295-4440

Bondhus, Protanium, ProGuard, BriteGuard, GoldGuard and ColorGuard are trademarks of Bondhus Corporation.

Distributed by: