

Biscuit® AC



AC Centrifugal Blower

FEATURES:

- Size: 4.75" x 1.56" deep (120mm x 40mm)
- Air Flow: 22 CFM
- Voltage: 115 & 230 VAC (50/60 Hz)
- Operating Temperature Range: -10°C to +70°C
- Storage Temperature Range: -40°C to +85°C
- Ball Bearings or Sleeve Bearings
- Terminals
- Weight: 18 oz. (.51 Kg)



PERFORMANCE:

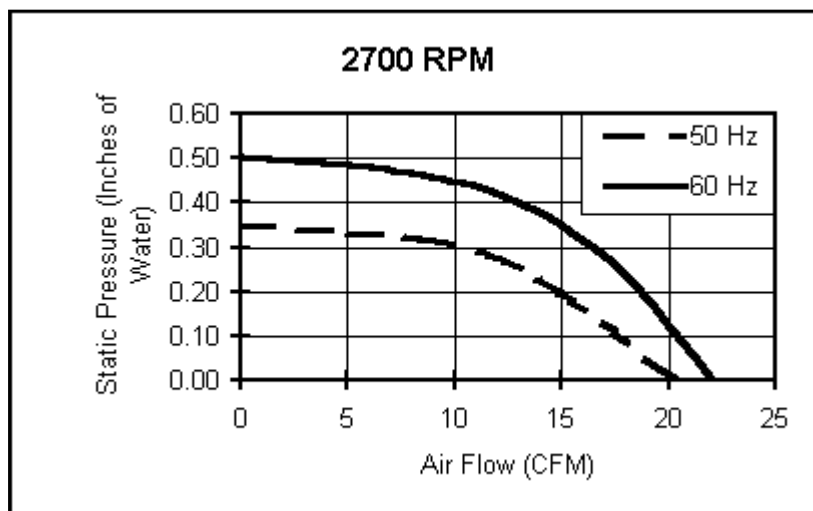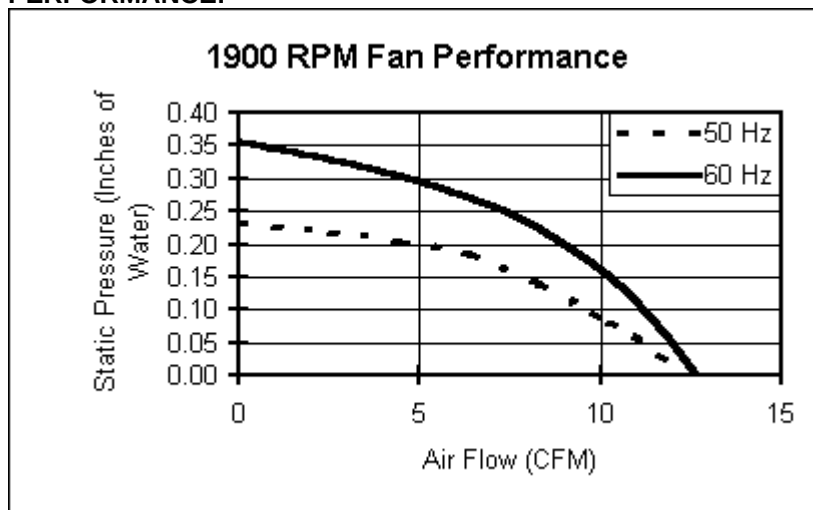

SPECIFICATIONS:

Model No.	Part No.	VAC	Watts	Running Current (Amps)	Locked Rotor Current (Amps)	RPM	CFM	dBA	Features
BT2A1	028448	115	15.2/14.5	.19/.17	.25/.24	2500/2700	20/22	48.2/49.6	2, 3
BT2B1	028454	115	15.2/14.5	.19/.17	.25/.24	2500/2700	20/22	48.2/49.6	2, 4
BT2M1	032192	115	11/10	.11/.11	.155/.140	1800/1900			
BT3A1	028449	230	13/14	.09/.08	.115/.110	2500/2700	20/22	48.2/49.6	2, 3
BT3B1	028732	230	13/14	.09/.08	.115/.110	2500/2700	20/22	48.2/49.6	2, 4

FEATURES:

1. Leadwires
2. Terminals
3. Ball Bearings
4. Sleeve Bearings
5. Tachometer Output
6. Thermal Speed Control
7. Programmable Speed Control
8. Fan Performance Sensor

MOTOR:

- Shaded Pole Motor, Single Phase
- Insulation Class B
- Ball Bearings or Sleeve Bearings
- Impedance Protected
- 100% Dielectric Tested

CONSTRUCTION:

- Housing - Polycarbonate, Black, UL94V-0
- Impeller - Polypropylene, Black, UL94V-0

LIFE EXPECTANCY:

- L10 Data - 82,000 hrs, @ 40°C

OPTIONS:

- Customized Harness Assemblies

