



Aluminium Housed Proximity Magnet
Part Number : PRM-SA-003
Product Data Sheet

PICTURE

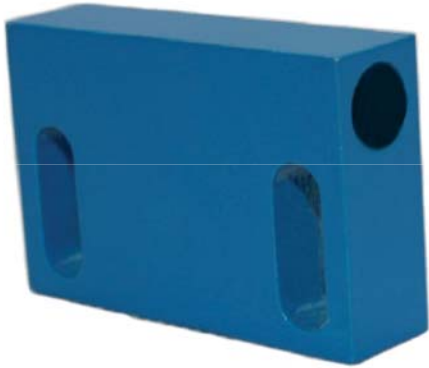

DIMENSIONS

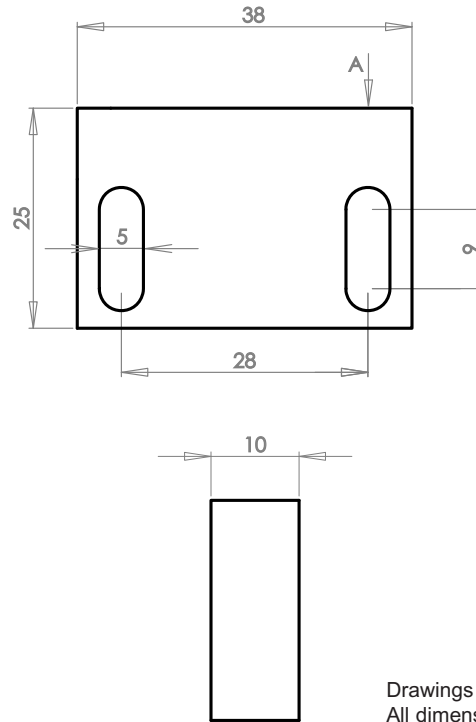

Drawings not to scale
 All dimensions in mm nominal

✓ RoHS Compliant

SPECIFICATION

| | | |
|--------------------------|-----------|-------------------------|
| Size | Length mm | 38 |
| | Width mm | 10 |
| | Height mm | 25 |
| Gauss Strength / Surface | Max | 800 (at point A) |
| Operating Temperature | Celsius | -20° to 85° |
| Case Material | | Powder coated Aluminium |
| Magnet | | Neodymium N35 |

Applications Include

- Position and Limit sensing.
- Machinery safety guard.
- Automated production line.
- Security alarm system.

Options/Features

- Robust sealed magnet.
- Powder coated to resist corrosion.
- Strong Neodymium magnet.

Did you know we also sell?



Rev. No.

Revision Note

Date

Signature

1

Datasheet

19-07-12

ML



As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone : +44 (0)1255 862236

www.assemtech.co.uk

Fax: +44 (0)1255 862014

©2012 Copyright Assemtech Europe Ltd, Unit 7, Rice Bridge Industrial Estate, Thorpe - Le - Soken, Essex, CO16 0HL, ENGLAND.
 USA: Comus International:+1 973 777 6900, Belgium: Comus Belgium BVBA: +32 (0)12 390400