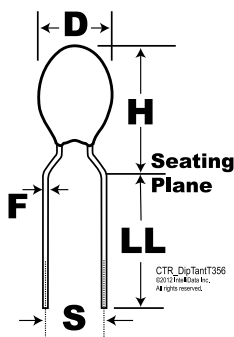


Capacitor, Tantalum, General Purpose Radial Conformal (Dipped), 3.3 uF, +/-20% Tol, 35V@85C, Lead Spacing=5.08 mm

**Dimensions (mm)**

Symbol	Dimension	Tolerance
D	5	
H	9.9	
F	0.5	+/-0.05
S	5.08	+/-0.38
LL	4.75	+/-0.81

Packaging Specifications

Package Kind:	Bulk
Package Type:	Bag
Package Quantity:	1000

General Information

Supplier:	KEMET
-----------	-------

Specifications

Value:	3.3 uF
Voltage DC @ 85C:	35V
Voltage DC @ 125C:	23V
Tolerance:	+/-20%
Body Type:	Radial Conformal (Dipped)
Temperature Range:	-55/+125C
Application:	General Purpose
Termination Type:	Tin (Sn)
RoHS:	Yes
Leakage Current:	0.9 uA
Dissipation Factor:	5%