


Datasheet

Art.No. 56.702.5053.0

Feed-through terminal WKF 1,5 D1/2/35

Feed-through DIN rail terminal block with spring clamp connection for mounting on TS 35, nominal cross section 1.5 mm², width 4 mm, color gray

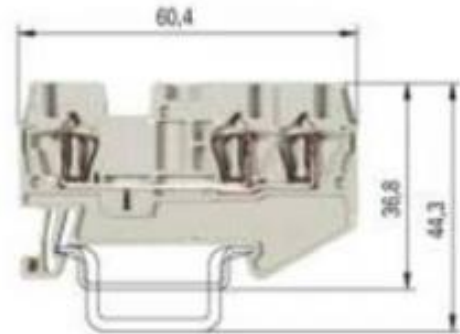

Art.No.	56.702.5053.0
EAN	4015573731783
Order unit	50 pieces

Approvals



Technical data

General

Nominal cross section	1.5 mm ²
Colour	Grey
Number of levels	1
Number of clamp positions per level	3
Width/grid dimension	4 mm
Insulating housing	PA666
Inflammability class of insulation material acc. with UL94	V0
Explosion-tested version "Ex e"	Yes
Mounting method	DIN rail (top hat rail) 35/7.5 mm
Terminal blocks for electrical installations	Yes

Technical data

Rated current	17.5 A
Rated voltage	500 V
Rated impulse voltage	6 kV
Pollution degree	3
Closing plate required	Yes
Length	60.4 mm
Type of insulation material	Thermoplastic

Connection Data

Connection type 1	Tension clamp connection
Connection type 2	Tension clamp connection

Minimum cross section solid	0.08 mm ²
Maximum cross section solid	1.5 mm ²
Minimum cross section fine stranded	0.08 mm ²
Maximum cross section fine stranded	1.5 mm ²
Wire strip length	10 mm

Technical Data UL/CSA

Cross section UL	26-14 AWG
Voltage UL	300 V
Current factory wiring	15 A
Current field wiring	15 A
Cross section CSA	26-14 AWG
Voltage CSA	300 V
Current CSA	15 A

Accessories

Art.No.:	Type:	Description
04.243.2053.0	Marking tag strips BZ/WKF 1,5	Marking strips for DIN rail terminal blocks with 4 mm width, unmarked
04.343.6953.8	Warning cover ADF 1,5/5	Cover with warning symbol for DIN rail terminal blocks type WKF ...
07.312.8353.0	End plate APF 1,5 D1/2	End plate for DIN rail terminal blocks type WKF..., color gray
07.312.8453.0	Partition TWF 1,5 D1/2	Partition for DIN rail terminal blocks type WKF ..., color gray
07.312.8953.0	End plate SAPF 1,5	End plate for DIN rail terminal blocks type WKF..., color gray
98.300.0000.0	Mounting rail 35x27x7,5EN60715 2000MM	Mounting rail TS 35, unslotted, size 7,5 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.300.1000.0	Mounting rail 35x27x7,5EN60715 2000MM	Mounting rail TS 35, slotted, size 7,5 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.300.1900.0	Mounting rail 35x27x7,5EN60715 2000MM	Mounting rail TS 35, slotted, size 7,5 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.360.0000.0	Mounting rail 35x24x15 EN60715 2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.360.0004.0	Mounting rail 35x24x15 EN60715 2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material steel, hot galvanized
98.370.0000.0	Mounting rail 35x27x15(EN60715)2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.370.1000.0	Mounting rail 35x27x15(EN60715)2000MM	Mounting rail TS 35, slotted, size 15 mm, length 2 m, material steel. galv. zinc-plated and dichromated
98.380.0000.0	Mounting rail 35x24x15 EN60715 2000MM	Mounting rail TS 35, unslotted, size 15 mm, length 2 m, material E copper
Z4.243.2053.0	Marking tag strips BZ/WKF 1,5/10	Marking strips for DIN rail terminal blocks with 4 mm width, unmarked
Z5.522.7453.0	End bracket 9708 / S35	End clamp for mounting rail TS 35
Z5.522.8553.0	End bracket 9708 / 2 S 35	End clamp for mounting rail TS 35
Z5.523.5653.0	End bracket WE 2 / U	End clamp for mounting rail TS 35 and TS 32
Z5.523.5753.0	End bracket WE 1 / U	End clamp for mounting rail TS 35 and TS 32
Z5.523.9353.0	End bracket WEF 1 / 35	End clamp, schraubenlos for mounting rail TS 35
Z7.268.0227.0	Jumper bar IVB WKF 1,5- 2	Cross connector, insulated for DIN rail terminal blocks type WKF..., 2 -pole
Z7.268.0327.0	Jumper bar IVB WKF 1,5- 3	Cross connector, insulated for DIN rail terminal blocks type WKF..., 3 -pole
Z7.268.0427.0	Jumper bar IVB WKF 1,5- 4	Cross connector, insulated for DIN rail terminal blocks type WKF..., 4 -pole
Z7.268.0527.0	Jumper bar IVB WKF 1,5- 5	Cross connector, insulated for DIN rail terminal blocks type WKF..., 5 -pole

Z7.268.1027.0	Jumper bar IVB WKF 1,5-10	Cross connector, insulated for DIN rail terminal blocks type WKF..., 10 -pole
Z7.268.2027.0	Jumper bar IVB WKF 1,5-20	Cross connector, insulated for DIN rail terminal blocks type WKF..., 20 -pole

Drawings

