


3 pole – Single I/O Multi-Ports

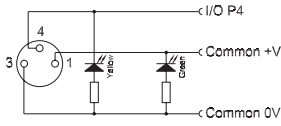

Function	Cable Colour	M16 Connector Pin No	Function	Cable Colour	M16 Connector Pin No	Function	Cable Colour	M16 Connector Pin No
+V	Brown	A&M	Port 5 P4	Pink	G	Port 9 P4	White/Blue	C
0V	Blue	L&U	Port 6 P4	Red	R	Port 10 P4	Brown/Blue	N
Port 1 P4	White	P	Port 7 P4	Black	E			
Port 2 P4	Green	J	Port 8 P4	Violet	O			
Port 3 P4	Yellow	T						
Port 4 P4	Grey	S						

Cable
Length (m)

 
 
 
 
 
 
 
 
Integral End Cable Entry

4 Port

6 Port

8 Port

10 Port



PUR	Length (m)	4 Port	6 Port	8 Port	10 Port
	5.0	BEY401P-FBP-05	BEY601P-FBP-05	BEY801P-FBP-05	BEYA01P-FBP-05
	10.0	BEY401P-FBP-10	BEY601P-FBP-10	BEY801P-FBP-10	BEYA01P-FBP-10
	20.0	BEY401P-FBP-20	BEY601P-FBP-20	BEY801P-FBP-20	BEYA01P-FBP-20

 
 
 
 
 
 
 
Integral Top Cable Entry

4 Port

6 Port

8 Port

10 Port



PUR	Length (m)	4 Port	6 Port	8 Port	10 Port
	5.0	BNY401P-FBP-05	BNY601P-FBP-05	BNY801P-FBP-05	BNYA01P-FBP-05
	10.0	BNY401P-FBP-10	BNY601P-FBP-10	BNY801P-FBP-10	BNYA01P-FBP-10
	20.0	BNY401P-FBP-20	BNY601P-FBP-20	BNY801P-FBP-20	BNYA01P-FBP-20

 
 
 
 
 
 
 
 
Integral M16 Home Run Connector

4 Port

6 Port

8 Port

10 Port



See top of page 7 for connectors

BNY401P-FBC	BNY601P-FBC	BNY801P-FBC	BNYA01P-FBC
-------------	-------------	-------------	-------------