

QUICK CONNECT SOCKET OUTLETS

QUICK CONNECT[®]




Panel Mounting Socket Outlet


Straight FLANGE 75 x 75mm

- Screwless terminals maintenance free
- Flange 74 x 75mm

IP44 *Splashproof*



A CURRENT	V VOLTAGE	Hz FREQUENCY	 2P+E	EARTH HR POS.	 3P+E	EARTH HR POS.	 3P+N+E	EARTH HR POS.
16 IP44	110	50-60	13685	4				
	240	50-60	13686	6				
	415	50-60			13693	6	132001	6
32 IP44	110	50-60	13702	4				
	240	50-60	13703	6				
	415	50-60			13710	6	132002	6

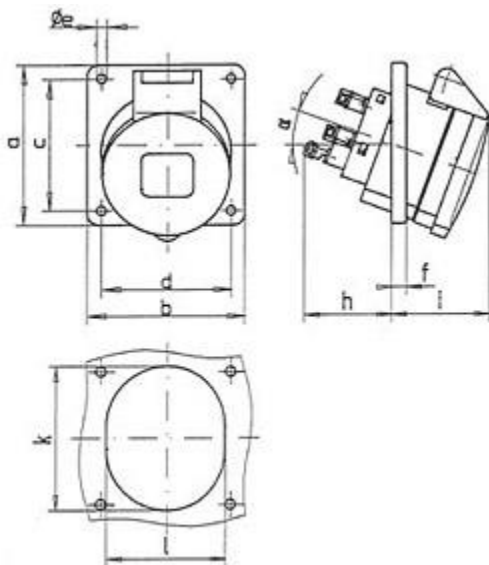

Amperes Poles	16			32		
	3	4	5	3	4	5
a	74	85	85	85	85	85
b	62	85	85	85	85	85
c	60	70	70	70	70	70
d	52	70	70	70	70	70
ø e	5.5	5.5	5.5	5.5	5.5	5.5
f	8	8	8	8	8	8
h	46	46	46	61	61	61
i	48	58	60	68	68	69
k	57	-	-	-	-	-
l	52	65	70	78	78	78
a	20°	20°	20°	20°	20°	20°
Conductor mm ² min	1.5	1.5	1.5	2.5	2.5	2.5
Conductor mm ² max	4	4	4	10	10	10