


Nominal Voltage:	1.4 V
Rated Capacity:	175 mAh at 1500 ohm to 1.1 V
Nominal Internal Impedance:	7.5 ohm @ 1kHz
Average Weight:	0.5 gm
Volume:	0.18 cm <sup>3</sup>
Terminals:	Flat
Operating Temperature Range:	0°C to 50°C (32°F to 122°F)
ANSI:	7002 ZD
IEC:	PR41

Typical Discharge Characteristics at 21 °C (70 °F)

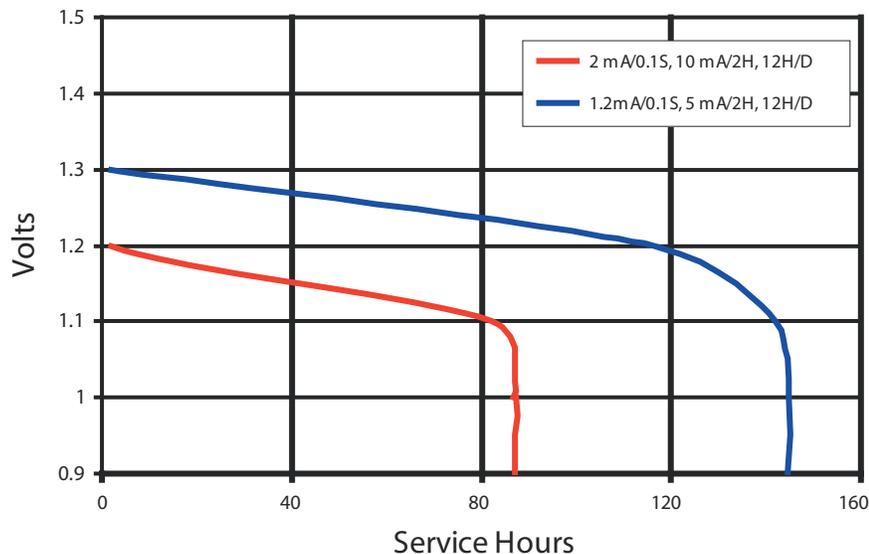

## DURACELL® BATTERIES

Berkshire Corporate Park  
Bethel, CT 06801 U.S.A.  
Telephone: Toll-free 1-800-544-5454  
Internet: [www.duracell.com](http://www.duracell.com)

\* Delivered capacity is dependent on the applied load, operating temperature and cut-off voltage. Please refer to the charts and discharge data shown for examples of the energy / service life that the battery will provide.