



RECHARGEABLE HAND TORCHES

RECHARGEABLE
HAND TORCHES

T9530R LED RECHARGEABLE HAND TORCH SET 300 LUMENS

The conveniently compact T9530R is a high performance hand torch with a rechargeable lithium-ion battery.

Specification:

- > High Power 300 Lumen Cree XM-L T6 LED
- > 3 Lighting modes: high, dimmed, flash
- > One-handed rapid slide focus mechanism - spot (x1) to flood (x6)
- > Beam intensifying plano-convex optical lens
- > Robust high grade aluminium body
- > Water & dirt resistant, tested to IP64
- > Battery life: high - 3.5hrs, dimmed - 8hrs
- > Size: 131 x 34mm





NEW

Beam	Max Range	Weather Rating	Impact Resistant	Power Supply	Battery Life
Spot x1 : Flood x6	250m	IP64	1M	1x Rechargeable 18650 Li-ion Batteries (supplied)	Up to 8 hours



300 LUMENS

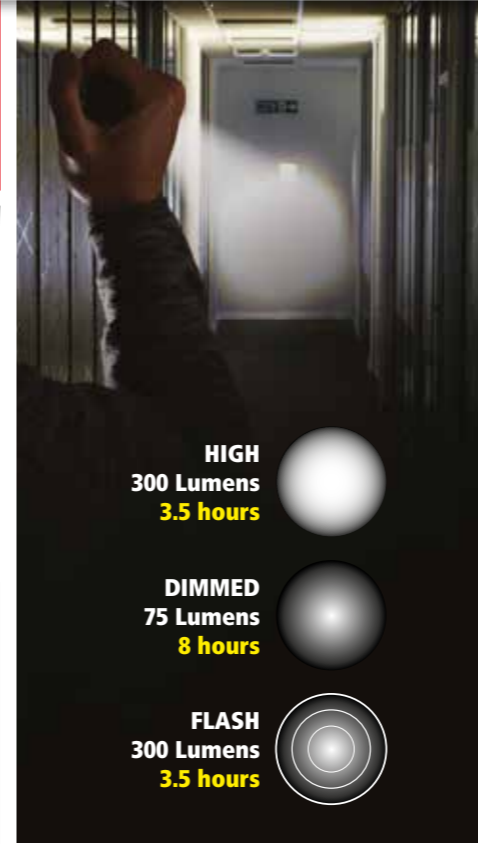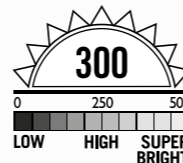

HIGH
300 Lumens
3.5 hours

DIMMED
75 Lumens
8 hours

FLASH
300 Lumens
3.5 hours

3x modes high/dimmed/flash



T9540R LED RECHARGEABLE HAND TORCH SET 400 LUMENS

Supplied with rechargeable lithium-ion batteries, the T9540R is a hugely powerful search light capable of casting a wide beam of light a very long way.

Specification:

- > High Power 400 Lumen Cree XM-L T6 LED
- > 3 Lighting modes: high, dimmed, flash
- > Compound spot & flood beam
- > Extra large 40mm aluminium reflector
- > Robust high grade aluminium body
- > Water & dirt resistant, tested to IP64
- > Battery life: high - 3.5hrs, dimmed - 7hrs
- > Size: 235 x 55mm




NEW

Beam	Max Range	Weather Rating	Impact Resistant	Power Supply	Battery Life
Compound spot & flood beam	350m	IP64	1M	2x Rechargeable 18650 Li-ion Batteries (supplied)	Up to 7 hours



400 LUMENS

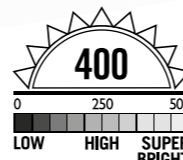

Extra large aluminium reflector

