


#3127 CT - D-subminiature pins and sockets crimp tool



Features

- Crimps D-subminiature pins and sockets
- (Ref:AMP 90312)
- The conductor and insulation crimps conform to O.E.M. specifications and are produced on one tool closure.
- Conductor crimps are "b" type, insulated crimps are "Oval" which are produced in two cavities: 28-24 AWG and 24-20 AWG.
- An easy load locator and wire stop are provided to orient the pins or sockets during crimping.

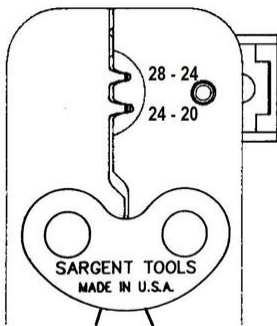

Item #	3127 CT
Item Application	D-subminiature pins & sockets
Connector/Terminal Type	D-subminiature pins & sockets Ref: AMP 90312
Cable/Crimp Type	Conductor crimp - "B" type, Insulation crimp - "Oval" type, 2 cavities
Crimp/HEX/Wire Sizes	28-24 AWG
Product Length	9 inches / 22.86 cm
Product Weight	15 ounces / .42 kgs