

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022011143](#)
Status: **Planned for Obsolescence**
Overview: [kk](#)
Description: 2.50mm (.098") Pitch KK® Wire-To-Board Housing, Female, Friction Lock, for 4809 Crimp Terminal, 14 Circuits

Documents:

[3D Model](#) [Product Specification PS-99020-0088 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR19980
TUV	R72090224
UL	E29179

General

Product Family	Crimp Housings
Series	5051
Application	Signal
Overview	kk
Product Name	KK®

Physical


Circuits (maximum)	14
Color - Resin	Natural (White)
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Nylon
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm (.098")
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Old Part Number	5051-14M
-----------------	----------

Reference - Drawing Numbers

Product Specification	PS-99020-0088
Sales Drawing	SDE-5051-NM-*

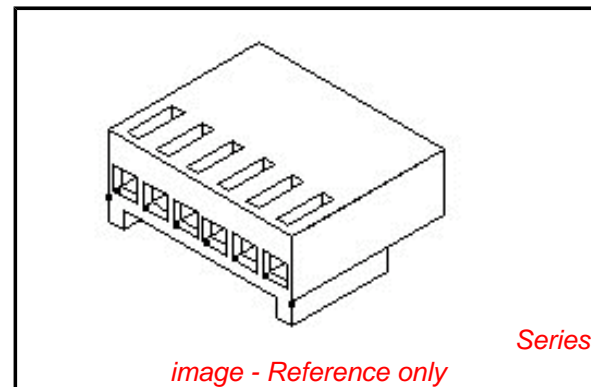

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[5051Series](#)

Mates With

[5045 Vertical Header](#), [5046 Right Angle Header](#)

Use With

[4809](#)