

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

52808-2671

Status:

Active

Overview:

FFC-FPC (SMT)

Description:

1.00mm Pitch Easy-On™ Type FFC/FPC Connector, Housing Assembly, Vertical, Non-ZIF Receptacle, 26 Circuits, Lead-Free

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E29179

General

Product Family

FFC/FPC Connectors

Series

52808

Overview

FFC-FPC (SMT)

Product Name

Easy-On™

UPC

822348136353

Physical

Circuits (Loaded)

26

Circuits (maximum)

26

Color - Resin

Natural

Contact Position

N/A

Durability (mating cycles max)

10

Entry Angle

Vertical

Mated Height

5.05mm

Material - Metal

Phosphor Bronze

Material - Plating Mating

Tin-Bismuth

Material - Plating Termination

Tin-Bismuth

Material - Resin

High Temperature Thermoplastic

Net Weight

647.500/mg

Number of Rows

1

Orientation

Vertical

PCB Locator

No

PCB Retention

None

Packaging Type

Embossed Tape on Reel

Pitch - Mating Interface

1.00mm

Pitch - Termination Interface

1.00mm

Polarized to PCB

No

Stackable

No

Surface Mount Compatible (SMC)

Yes

Temperature Range - Operating

-20°C to +80°C

Termination Interface: Style

Surface Mount

Wire/Cable Type

FFC/FPC

Electrical


Current - Maximum per Contact

0.5A

Voltage - Maximum

125V AC (RMS)/DC

Material Info

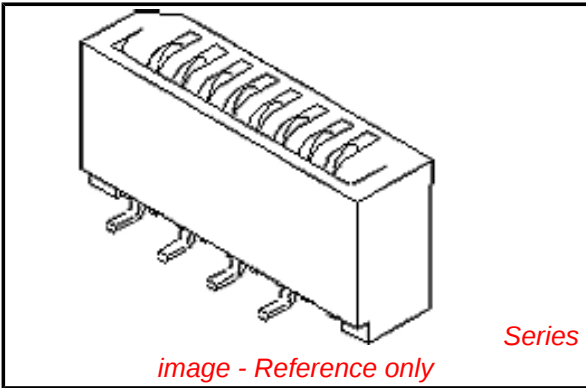

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

52808Series

Mates With

Molex Premo-Flex FFC. Be sure to match like plating

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION