

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

47408-0001

Status:

Active

Overview:

High Definition Multimedia Interface (HDMI)* Products

Description:

0.50mm Pitch HDMI* Receptacle, Right Angle, Reverse, without Dimple and Mylar, 0.76µm Gold (Au) Plating, Matte Tin Plating on Shell, 19 Circuits, Lead-Free


Documents:

3D Model

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	I/O Connectors
Series	47408
Application	Wire-to-Board
Comments	Without Dimple, Without Mylar
Component Type	Receptacle
Overview	High Definition Multimedia Interface (HDMI)* Products
Product Name	HDMI
Type	N/A
UPC	822350586405
Physical	
Boot Color	N/A
Circuits (Loaded)	19
Circuits (maximum)	19
Color - Resin	Black
Gender	Male
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Tin-Bismuth
Material - Resin	High Temperature Thermoplastic
Net Weight	2.164/g
Number of Rows	2
Orientation	Right Angle
PCB Locator	Yes
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Panel Mount	No
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	0.762µm
Plating min - Termination	1.016µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Temperature Range - Operating	-20°C to +85°C
Termination Interface: Style	Surface Mount
Waterproof / Dustproof	No
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	0.5A
Shield Type	Full Shield
Shielded	Yes

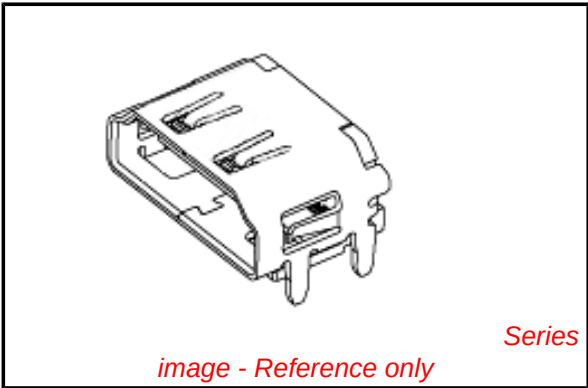

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

47408Series

Mates With

HDMI Cables

Voltage - Maximum	40V DC
-------------------	--------

Solder Process Data

Duration at Max. Process Temperature (seconds)	10
Lead-free Process Capability	Reflow Capable (SMT only)
Max. Cycles at Max. Process Temperature	1
Process Temperature max. C	250

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-47408-001
---------------	--------------

* High Definition Multimedia Interface and HDMI are trademarks of HDMI Licensing, LLC.

This document was generated on 11/14/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION