


DESTB-1002

2 Pole steatite ceramic high temperature blocks terminal 57a 750v



Product Image
Not Available

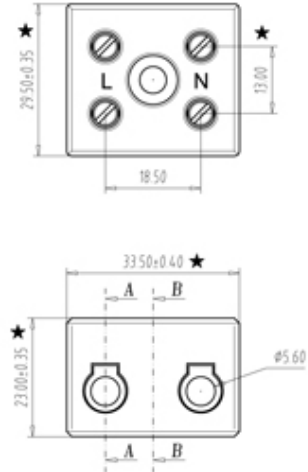

SPECIFICATION

Number of Poles	2
Body Material	Steatite
Colour	White
Min Conductor Size (Sq mm)	2.5
Max Conductor Size (Sq mm)	10
Min Conductor Size AWG	22
Max Conductor Size AWG	8
Max Current (A)	57
Max Voltage (V)	750
Minimum Temp Rating °C	-40
Max Temp Rating °C	200
Pitch (mm)	18.5
Height (mm)	21
Width (mm)	22
Length (mm)	24
Comments	M4 conductor clamping screws, maximum torque=1.2Nm

DISTRIBUTORS

