


INTERFACE MODULES & SUPPORTS

USB A Interface Module

- Single USB A type socket to screw terminals **CIM/USBA**

- Terminals marked +5V, D-, D+ and GND
- Separate shield connection
- 35mm DIN rail mounting
- Option for 32mm (G) rail mounting
- Available with optional wall mounting plates
- 45° terminals for easy access
- RoHS compliant
- SVHC free (2012)

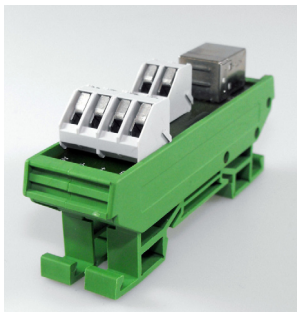

SPECIFICATION

Rating	30V DC 100mA		
Cable entry	0.2-4mm ² (30-12 AWG)		
Terminal screw	M3		
Strip length	6mm (0.24")		
Max terminal torque	0.5Nm (4lb-in)		
Dimensions:	Height:	Width:	Length:
CIM/USBA	44mm (1.73")	83mm (3.27")	26mm (1.02")


TYPE NO. DESCRIPTION

CIM/USBA	USB A to screw terminal interface. 35 mm din rail mounting
----------	--

USB B Interface Module

- Single USB B type socket to screw terminals **CIM/USBB**

- Terminals marked +5V, D-, D+ and GND
- Separate shield connection
- 35mm DIN rail mounting
- Option for 32mm (G) rail mounting
- Available with optional wall mounting plates
- 45° terminals for easy access
- RoHS compliant
- SVHC free (2012)

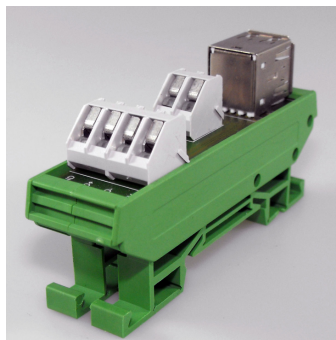

SPECIFICATION

Rating	30V DC 100mA		
Cable entry	0.2-4mm ² (30-12 AWG)		
Terminal screw	M3		
Strip length	6mm (0.24")		
Max terminal torque	0.5Nm (4lb-in)		
Dimensions:	Height:	Width:	Length:
CIM/USBB	41mm (1.61")	83mm (3.27")	26mm (1.02")

TYPE NO. DESCRIPTION

CIM/USBB	USB B to screw terminal interface. 35 mm din rail mounting
----------	--