


PCB TERMINAL BLOCKS

5.08mm Pitch Low Profile 45° Rising Clamp Terminal

- 2 & 3 pole interlocking
- 4-12 pole pre-assembled
- 45° mounting
- Moulded in grey UL94-V0 flame retardant PA
- Professional rising clamp terminals
- 0.2-4.0mm² (30-12AWG) solid cable
- 0.2-2.5mm² (30-12AWG) stranded cable
- Captive screw
-    approved


CTB3008

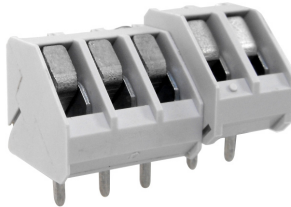

TYPE NO.	POLES	LENGTH
CTB3008/2	2	10.2mm
CTB3008/3	3	15.2mm
CTB3008/4	4	20.3mm
CTB3008/5	5	25.4mm
CTB3008/6	6	30.5mm
CTB3008/7	7	35.6mm
CTB3008/8	8	40.64mm
CTB3008/9	9	45.7mm
CTB3008/10	10	50.8mm
CTB3008/11	11	55.9mm
CTB3008/12	12	61mm

SPECIFICATION

Rating	24A/160V UL=16A/300V, VDE&IMQ=24A/130V
Dielectric strength	≥1.25kV
Impulse withstand voltage	4kV
Working temperature	110°C
Moulding	UL94-V0 flame retardant PA
Pin/terminal	Tinned, nickel plated brass
Wire clamp	Nickel plated brass
Screw/torque	M3 steel zinc plated, 0.5Nm
Recommended PCB hole size	ø1.3mm

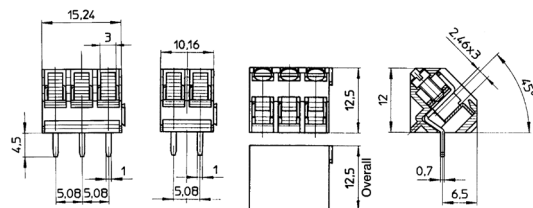

PCB
TERMINAL
BLOCKS

INTER-
CONNECTION

FUSES &
FUSE-
HOLDERS

LEDs &
INDICATORS

MINIATURE
SWITCHES

LIMIT &
SAFETY
SWITCHES

CONTROL
PRODUCTS

INTERFACE
MODULES &
SUPPORTS

RELAY
BASES

ENCLOSURES

BATTERIES

TRANS-
FORMERS