

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


51347-0200

Status:

Active

Description:

3.30mm Pitch Wire-to-Wire Receptacle Housing, Positive Lock, Single Row, 2 Circuits, White

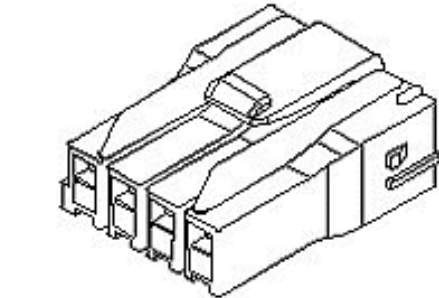

Series

image - Reference only

Documents:

- [3D Model](#)
- [Drawing \(PDF\)](#)
- [Product Specification PS-51284-001 \(PDF\)](#)
- [Product Specification PS-51284-002 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Housings
Series	51347
Application	Signal, Wire-to-Wire
Product Name	N/A
UPC	800756598970

Physical

Circuits (maximum)	2
Color - Resin	Natural
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	500.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-25°C to +85°C

Electrical

Current - Maximum per Contact	4A
-------------------------------	----

Material Info

Reference - Drawing Numbers

Product Specification	PS-51284-001, PS-51284-002, RPS-51284-003, RPS-51284-004, RPS-51284-006, RPS-51284-007, RPS-51284-008, RPS-51284-009, RPS-51284-011, RPS-51284-014, RPS-51347-002, RPS-51347-003
Sales Drawing	SD-51347-001, SD-51347-002

EU RoHS

ELV and RoHS
Compliant

REACH SVHC

Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product
environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

51347Series

Mates With

51346-0200

Use With

51348 , 56187

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION