

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

39421-0002

Status:


Active

Overview:

Eurostyle™ Terminal Blocks

Description:

12.00mm Pitch Beau™ EuroMax™ Horizontal Plug, 2 Circuits

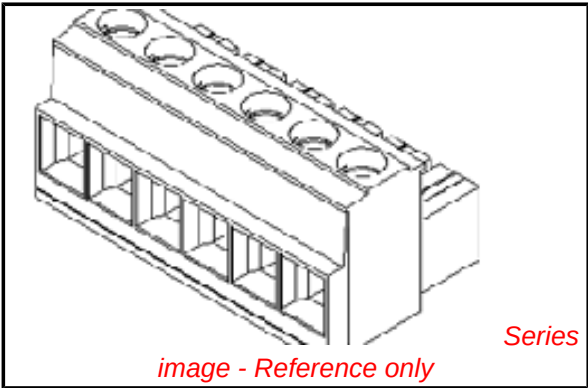

Documents:

3D Model

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Terminal Blocks
Series	39421
Application	N/A
Component Type	Plug
Overview	Eurostyle™ Terminal Blocks
Product Name	EuroMax™ Pluggable
Type	Euro Block
UPC	822348530281
Physical	
Circuits (Loaded)	2
Color - Resin	Black
Entry Angle	180° Angle
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	45.020/g
Number of Rows	1
Orientation	Horizontal
PCB Retention	N/A
Panel Mount	No
Pitch - Mating Interface	12.00mm
Pitch - Termination Interface	12.00mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	130°C
Wire Size AWG	10, 12, 14, 3, 4, 6, 8
Electrical	
Current - Maximum per Contact	85A
Voltage - Maximum	600V
Material Info	
Old Part Number	420502
Reference - Drawing Numbers	
Sales Drawing	SD-39421-001

EU RoHS

RoHS Compliant by Exemption

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS

50

Pb

Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

39421Series

Mates With

39425-0002 Horizontal PCB Header

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION